

52123100	DATA SHEET	
Valid from: 04.10.2023	SKINDICHT® BL-M +FKM O-RING	

SKINDICHT® BL-M blind plugs are used wherever already existing housing holes are not yet required or no longer required.

Our blind plug model is equipped with a screwing slit, which makes installation significantly easier. The SKINDICHT® BL-M is qualified for use by machine, apparatus and electric motor construction.



Components:

Blind plug	Brass, nickel-plated Brass lead free, nickel-plated
O-ring	FKM


Technical features:

Connecting thread	M12x1,5 up to M63x1,5 acc. to EN 60423
Protection class	IP66, IP68 (10bar/30min) acc. to EN 60529
Temperature range	-20 °C up to +200 °C

Norm references:



M	Ø A [mm]	C [mm]	D [mm]	O-Ring [mm]	Article No.	
					Brass	Brass lead free
M12x1,5	14	7,5	5	9 x 2	52123100	52123100LF
M16x1,5	18	8	5	13 x 2	52123110	52123110LF
M20x1,5	22	9,5	6	17 x 2	52123120	52123120LF
M25x1,5	28	11	7	22 x 2	52123130	52123130LF
M32x1,5	35	12	8	28 x 2	52123140	52123140LF
M40x1,5	44	13	9	36 x 2	52123150	52123150LF
M50x1,5	54	15	9	46 x 2	52123160	52123160LF
M63x1,5	70	16	10	57 x 2	52123170	52123170LF

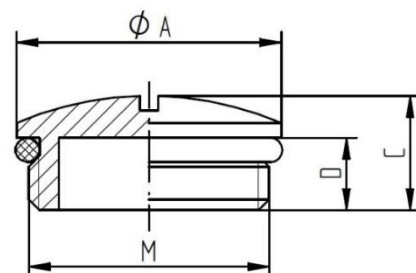

For more information, please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: MOME3/PDP Released: DAMU1/PDP	Document: DB52123100EN Version: 01	Page 1 of 1
---	---------------------------------------	-------------