

|                           |                                  |                                                                                     |
|---------------------------|----------------------------------|-------------------------------------------------------------------------------------|
| 52103405                  | <b>DATA SHEET</b>                |  |
| Valid from:<br>24.11.2023 | <b>SKINDICHT® BL-M hexagonal</b> |                                                                                     |

The SKINDICHT® BL-M hexagonal brass blind plugs with metric thread for ensuring the unused threaded holes are closed and sealed, incl. O-Ring.



### Components:

|        |                                                        |
|--------|--------------------------------------------------------|
| Body   | Brass, nickel-plated<br>Brass lead free, nickel-plated |
| O-Ring | NBR<br>(On request VITON® O-Ring)                      |

### Technical features:

|                   |                                        |
|-------------------|----------------------------------------|
| Connecting thread | M12x1,5 up to M63x1,5 acc. to EN 60423 |
| Protection class  | IP68 - 5bar, test acc. to EN 60529     |
| Temperature range | -30 °C up to +100 °C                   |

### Norm references:




VITON® is a registered trademark of DuPont de Nemours.

.

|                                                  |                                       |             |
|--------------------------------------------------|---------------------------------------|-------------|
| Creator: T. Dvoulity /PDP<br>Released: DAMU1/PDP | Document: DB52103405EN<br>Version: 05 | Page 1 of 2 |
|--------------------------------------------------|---------------------------------------|-------------|

|                           |                                  |                                                                                     |
|---------------------------|----------------------------------|-------------------------------------------------------------------------------------|
| 52103405                  | <b>DATA SHEET</b>                |  |
| Valid from:<br>24.11.2023 | <b>SKINDICHT® BL-M hexagonal</b> |                                                                                     |

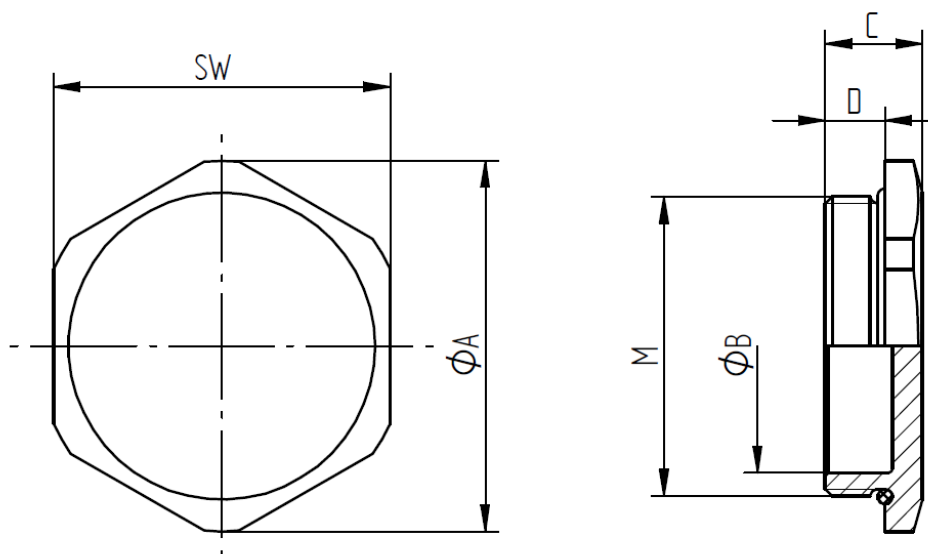

| Thread M | SW<br>[mm] | Ø A<br>[mm] | Ø B<br>[mm] | C<br>[mm] | D<br>[mm] | Article No. |                    |
|----------|------------|-------------|-------------|-----------|-----------|-------------|--------------------|
|          |            |             |             |           |           | Brass       | Brass<br>lead free |
| M12x1,5  | 16         | 17,8        | 8,2         | 8         | 5         | 52103405    | 52103405LF         |
| M16x1,5  | 20         | 22          | 12,1        | 8         | 5         | 52103415    | 52103415LF         |
| M20x1,5  | 24         | 26,4        | 16          | 9,5       | 6         | 52103425    | 52103425LF         |
| M25x1,5  | 29         | 31,9        | 20          | 11        | 7         | 52103435    | 52103435LF         |
| M32x1,5  | 36         | 39,6        | 26,2        | 12        | 8         | 52103445    | 52103445LF         |
| M40x1,5  | 45         | 49,5        | 33,8        | 13        | 8         | 52103455    | 52103455LF         |
| M50x1,5  | 54         | 59          | 42,2        | 15        | 9         | 52103465    | 52103465LF         |
| M63x1,5  | 67         | 73,5        | 55          | 16        | 10        | 52103475    | 52103475LF         |

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

|                                                  |                                       |             |
|--------------------------------------------------|---------------------------------------|-------------|
| Creator: T. Dvouletý /PDP<br>Released: DAMU1/PDP | Document: DB52103405EN<br>Version: 05 | Page 2 of 2 |
|--------------------------------------------------|---------------------------------------|-------------|