

52006600	DATA SHEET	
Valid from: 25.11.2021	SKINDICHT® BLK-M	

The SKINDICHT® BLK-M polystyrene blind plugs are used where unengaged threaded openings are to be closed.




Technical Features:

Connecting thread	M12x1.5 up to M63x1.5 acc. to DIN 60423
Material	Polystyrene, impact resistant
Temperature range	-25 °C up to +60 °C
Colour RAL	RAL 7035 light grey RAL 9005 black, on request
Protecting class	IP54 acc. to EN 60529
Flammability	According to UL94: HB

Norm references:



M	A (mm)	C (mm)	D (mm)	Part No.
M 12x1,5	15	8,7	7	52006600
M 16x1,5	20	8,9	7	52006610
M 20x1,5	24	10,3	7	52006620
M 25x1,5	30	11,3	8	52006630
M 32x1,5	37	11,8	8	52006640
M 40x1,5	46	12,7	8	52006650
M 50x1,5	56	14,8	10	52006660
M 63x1,5	70	16,6	12	52006670

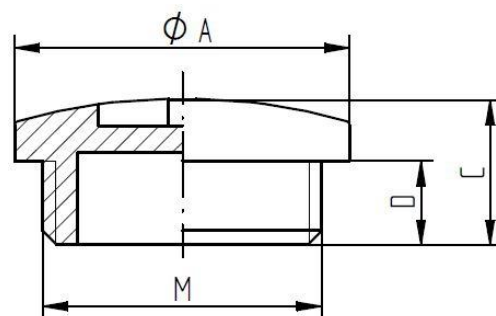

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: M. Jurak /PDP Released: DAMU1/PDP	Document: DB52006600EN Version: 05	Page 1 of 1
---	---------------------------------------	-------------