



Electric Leaner Actuators

Electric Leaner Actuators



- Type of duty: 10% 2 min on / 18 min off
- Protection class: IP65
- Operating temperature: -20 – 60 °C
- Limit switch: Inner

Item No.	Input Voltage	Stroke Length (mm)	No-load speed (mm/s)	Rated current (A)	Load Capacity (N)	Min. installation size (mm)	Cable length (mm)	Holl effect sensor
3373189	12 VDC	25±3	45±10%	3.3	150	130±3	700±20	No
3373190	24 VDC	25±3	7±10%	1.6	1000	130±3	700±20	No
3373191	12 VDC	50±3	16±10%	3.3	500	155±3	900±20	Yes
3373192	12 VDC	50±3	16±10%	3.3	500	155±3	700±20	No
3373193	24 VDC	50±3	45±10%	1.6	150	155±3	700±20	No
3373194	24 VDC	50±3	30±10%	1.6	250	155±3	700±20	No
3373195	24 VDC	50±3	16±10%	1.6	500	155±3	900±20	Yes
3373196	24 VDC	50±3	7±10%	1.6	1000	155±3	900±20	Yes
3373197	24 VDC	50±3	7±10%	1.6	1000	155±3	700±20	No
3373198	24 VDC	100±3	45±10%	1.6	150	205±3	700±20	No
3373199	24 VDC	100±3	30±10%	1.6	250	205±3	900±20	Yes
3373200	24 VDC	100±3	16±10%	1.6	500	205±3	900±20	Yes
3373201	24 VDC	100±3	7±10%	1.6	1000	205±3	700±20	No
3373202	24 VDC	100±3	7±10%	1.6	1000	205±3	900±20	Yes
3373203	24 VDC	100±3	6±10%	2.2	2500	205±3	700±20	No
3373204	24 VDC	300±3	45±10%	1.6	150	425±3	700±20	No
3373205	24 VDC	300±3	7±10%	1.6	1000	425±3	700±20	No



Datasheet – TRU Components


Item no.: 3373189 - 3373207




Electric Leaner Actuators

Push-rod Operation		
State	Red	Black
Stretch	+	-
Retraction	-	+


- Item No. 3373189, 3373190

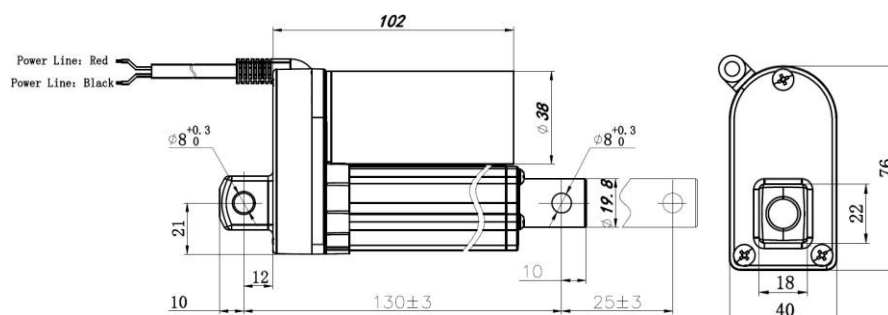

- Item No. 3373191, 3373195, 3373196

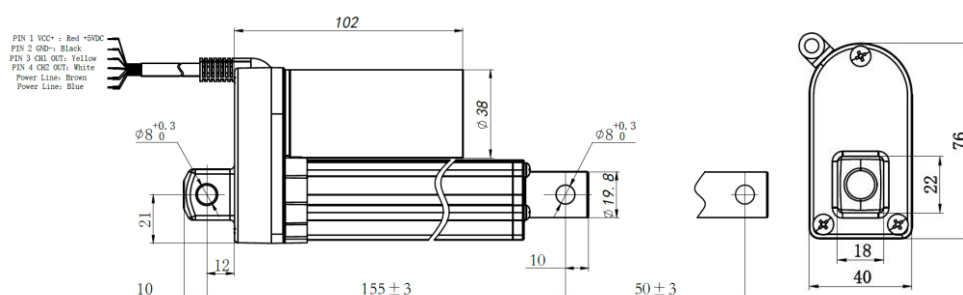

- Item No. 3373192, 3373193, 3373194, 3373197

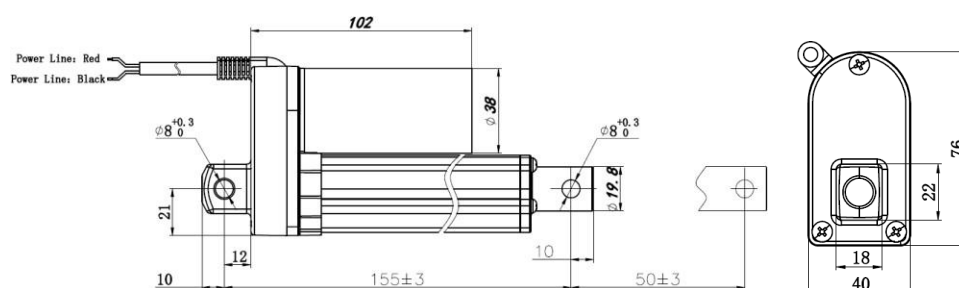




Datasheet – TRU Components

Item no.: 3373189 - 3373207




Electric Leaner Actuators


- Item No. 3373198, 3373201, 3373203

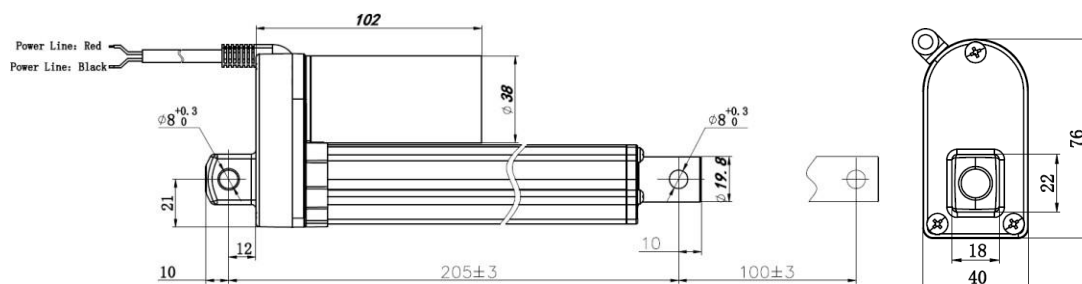

- Item No. 3373199, 3373200, 3373202

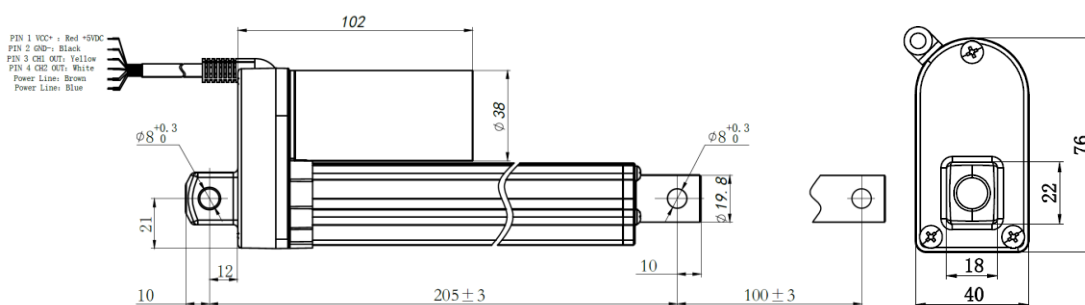

- Item No. 3373204, 3373205

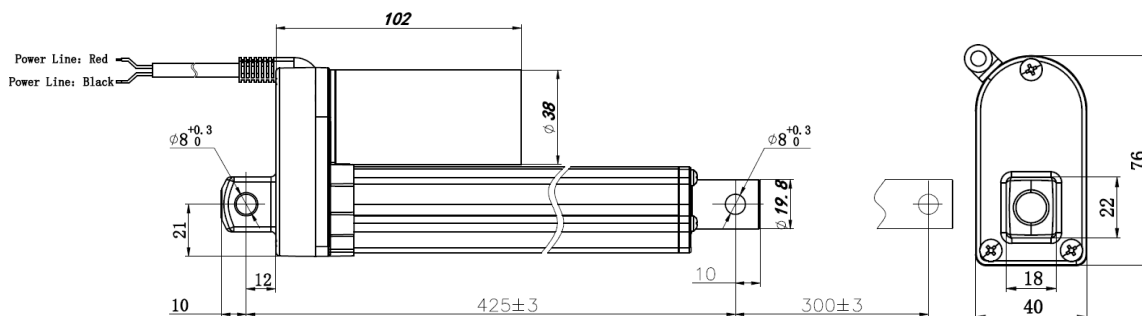


Datasheet – TRU Components

Item no.: 3373189 - 3373207



Electric Leaner Actuators

- Item No. 3373206
Mounting Bracket
No fillet 0.5 x 45°, no fillet R0.3
Unnoted linear dimensional tolerances shall meet the requirements of GB/T1804-2000m
Material: 6063-T5

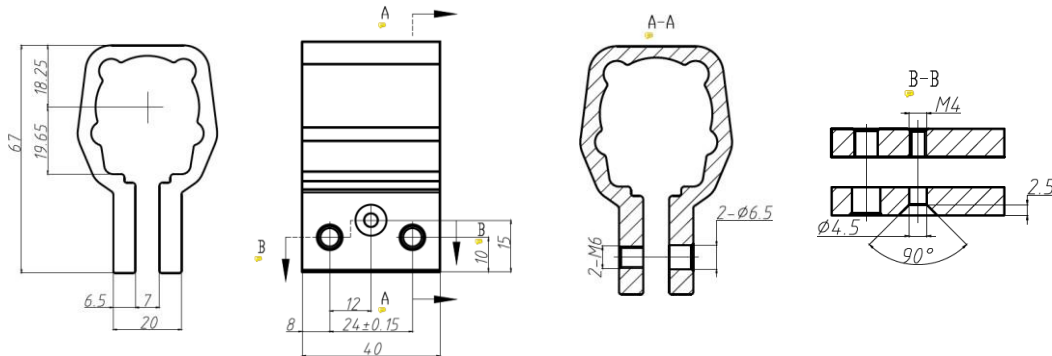

- Item No. 3373207
Mounting Bracket
No fillet 0.5 x 45°, no fillet R0.3
Matching pin shaft and cotter pin
Material: Low-carbon steel

