


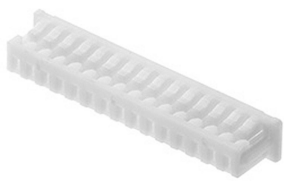

Part Number : 510211700
Product Description : 1.25mm Pitch,
PicoBlade Receptacle Crimp Housing, Single
Row, Friction Lock, 17 Circuits, Natural
Series Number : 51021
Status : New Business Not Supported
Product Category : Connector Housings



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	New Business Not Supported
Category	Connector Housings
Series	51021
Description	1.25mm Pitch, PicoBlade Receptacle Crimp Housing, Single Row, Friction Lock, 17 Circuits, Natural
Application	Signal, Wire-to-Board, Wire-to-Wire
Product Name	PicoBlade
UPC	800753750494

Agency

CSA	LR19980
UL	E29179

Physical

Circuits (maximum)	17
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	146.500/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C