


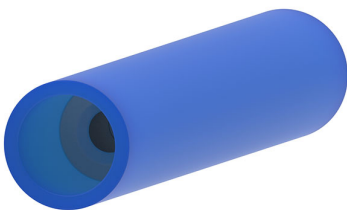

Part Number : [192020035](#)
Product Description : NylaKrimp Butt Splice
for 16-14 AWG Wire, Tape and Reel
Series Number : 19202
Status : Active
Product Category : Splices
Engineering Number : BS-N-331T



Documents & Resources

Drawings

[192020035_sd.pdf](#)

3D Models and Design Files

[192020035_stp.zip](#)

Specifications

[PS-19902-011-001.pdf](#)

[PS-19902-015-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Splices
Series	19202
Description	NylaKrimp Butt Splice for 16-14 AWG Wire, Tape and Reel
Product Name	Butt,NylaKrimp
UPC	800753047907

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed - Brazed
Color - Resin	Blue
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.328/g
Packaging Type	Adhesive Tape on Reel
Wire Size (AWG)	14, 16

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>192880098</u>

This document was generated on Feb 26, 2025