

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0354076802](#)
Status: **Active**
Description: 2.28mm Sealed Terminal, Female, 0.85-1.25mm² AVSS, 0.25mm Material Thickness, Pre-Tin Plated, Reel

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-35407-003-001 \(PDF\)](#)
[Product Specification PS-35519-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Terminals
Series [35407](#)
Application Power, Wire-to-Board
Crimp Quality Equipment Yes
Product Name N/A
UPC 756054240014


Physical

Gender Female
Material - Metal High Performance Alloy (HPA)
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.293/g
Packaging Type Reel
Plating min - Mating 0.813µm
Plating min - Termination 0.813µm
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.90mm max.
Wire Size AWG 16, 18
Wire Size mm² N/A

Material Info

Reference - Drawing Numbers

Crimp Specification CS-35407-6702-001
Packaging Specification PK-35407-003-001
Product Specification PS-35519-001-001
Sales Drawing SD-35407-001

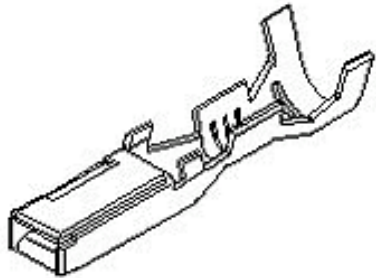

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/71/2019 (16 July
2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[35407](#) Series

Mates With

[35420](#)

Use With

[35825](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool for 2.28mm (.090") Sealed Receptacle Terminal	638257700
FineAdjust for 2.30mm (.090")	639027100

This document was generated on 11/21/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION