


DATASHEET

Pin connector with strain relief

Item No. 3384443

Overview

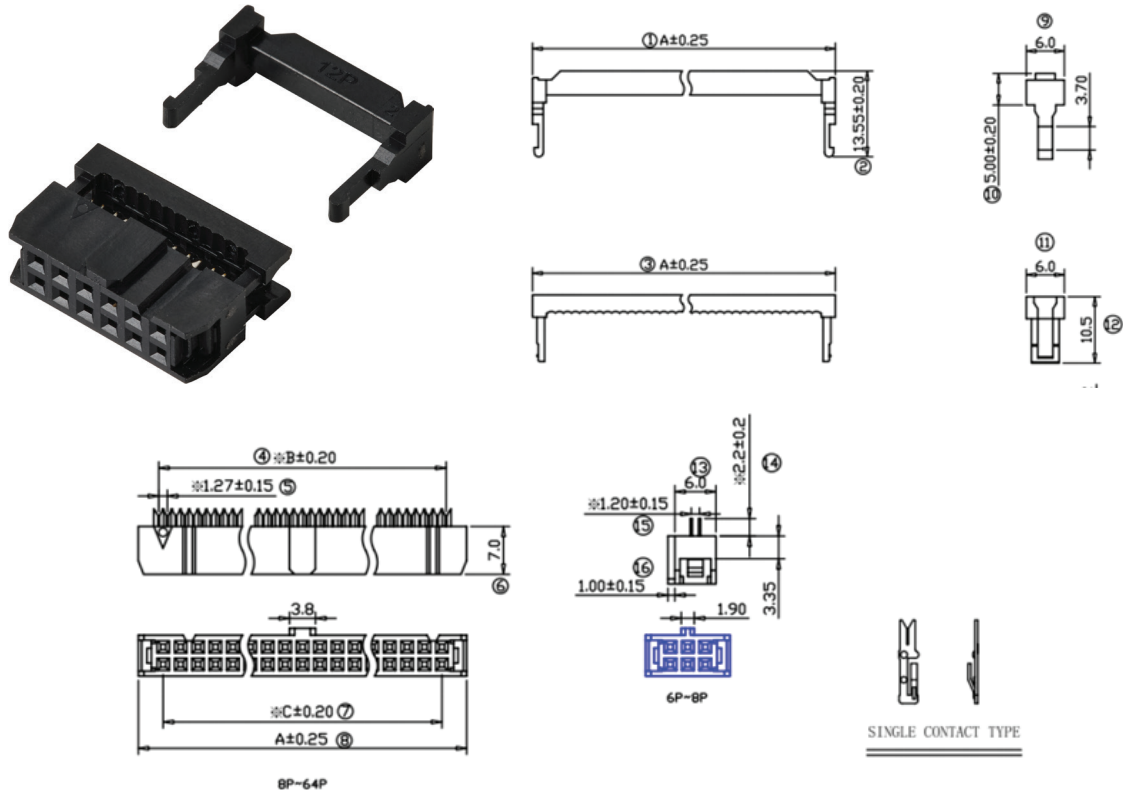

Features

- With strain relief

Technical data

Contact material	Copper alloy
Contact spacing	2.54 mm
Number of pins	12
Number of poles per row	6 mm
Current rating	1 A
Contact Resistance	max. 20 mΩ
Suitable for	Ribbon cable RM 1.27 mm
Plug direction	Perpendicular to the circuit board
Housing material	PBT
Product type	Post connector
Dimension (L x W x H)	19.94 x 6 x 7 mm
Connection	Insulation displacement
Operating Temperature	-40 to +105 °C

Pos.	Dim. A	Dim. B	Dim. C
12	19.94	13.97	12.70