
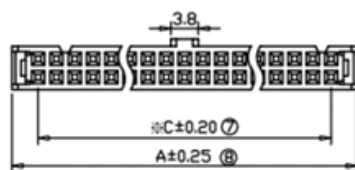
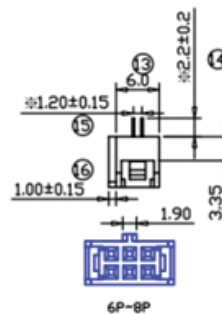
 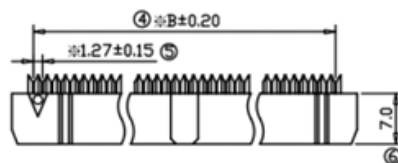
 
 



DATASHEET

Post connector with strain relief

Item No. 3384446

Overview

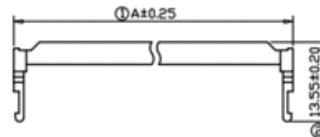

SINGLE CONTACT TYPE

8P-64P

Pos.	Dim. A	Dim. B	Dim. C
6	12.32	6.35	5.08

Features

- With strain relief

Technical data

Design	Socket strip
Special features	with strain relief
Contact spacing	2.54 mm
Number of rows	2
Number of pins per row	3
Number of pins	6
Current rating	1 A
Withstanding voltage	500 V/AC for 1 minute
Contact material	Copper alloy
Connection	Insulation displacement
Dimensions (L x W x H)	12.3 x 6 x 6.8 mm
Operating Temperature	-40 to +105°C
Product type	Post connectors
Wire size flat cable I.D.C.	1.27 mm Pitch