
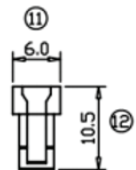
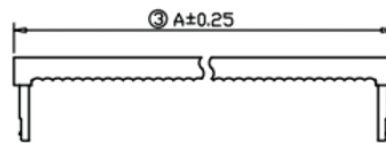
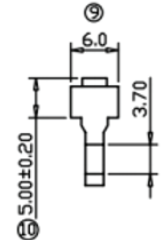


DATASHEET

Post connector with strain relief pitch

Item No. 3384448

Overview

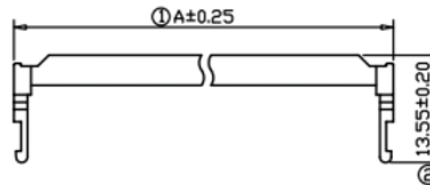

Pos.	Dim. A	Dim. B	Dim. C
20	30.10	24.13	22.86

Technical data

Connector type	Female connector, Power strip, straight
Contact material	Copper alloy
Housing material	PBT
Contact spacing	2.54 mm
Number of rows	2
Number of poles per row	10
Number of pins	20
Current rating	1 A
Withstanding voltage	500 V/AC for 1 minute
Connection	Insulation displacement
Dimension (L x W x H)	30.10 x 6 x 7 mm
Suitable for	Ribbon cable RM 1.27 mm
Plug direction	Perpendicular to the circuit board
Operating Temperature	-40 to +105 °C

