
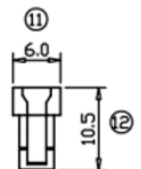
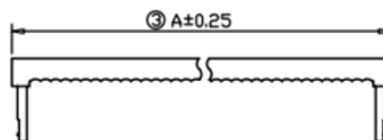
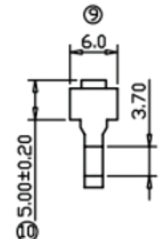


DATASHEET

Post connector with strain relief

Item No. 3384449

Overview

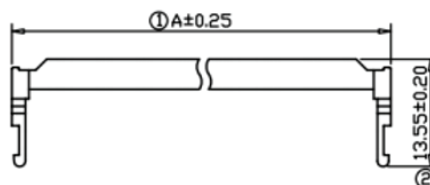

Pos.	Dim. A	Dim. B	Dim. C
8	14.86	8.89	7.62

Features

- Socket strip
- With strain relief

Technical data

Contact material	Copper alloy
Housing material	PBT
Contact spacing	2.54 mm
Number of rows	2
Number of poles per row	4
Number of pins	8
Current rating	1 A
Withstanding voltage	500 V/AC for 1 minute
Connection	Insulation displacement
Dimension (L x xW x H)	14.84 x 5.9 x 6.9 mm
Wire size flat cable I.D.C.	1.27 mm Pitch
Operating Temperature	-40 to 105 °C

