


DATASHEET

Post connector with mounting flange pitch

Item No. 3384451

Overview

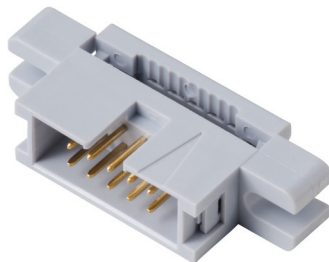

Technical data

Connector type	Pin strip, straight
Mounting flange	Yes
Contact material	Brass
Contact spacing	2.54 mm
Number of rows	2
Number of poles per row	5
Number of pins	10
Current rating	2 A
Withstanding voltage	500 V/AC for 1 minute
Connection	Insulation displacement
Dimension (L x W x H)	36.96 x 8.1 x 14.9 mm
Plug direction	Perpendicular to the circuit board
Housing material	PBT
Operating Temperature	-40 to +105°C

