
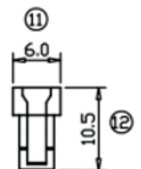
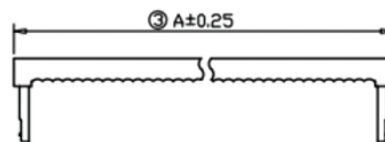
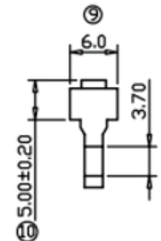


DATASHEET

Post connector with strain relief pitch

Item No. 3384454

Overview

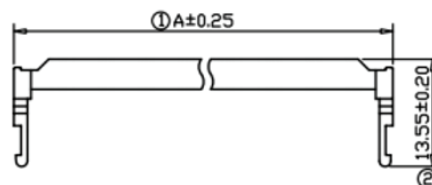

Pos.	Dim. A	Dim. B	Dim. C
26	37.72	31.75	30.48

Features

- Female connector
- Straight
- With strain relief

Technical data

Contact material	Copper alloy
Housing material.....	PBT
Contact spacing.....	2.54 mm
Number of rows	2
Number of poles per row	13
Number of pins	26
Current rating.....	1 A
Withstanding voltage	500 V/AC for 1 minute
Connection	Insulation displacement
Dimension (L x W x H).....	37.72 x 6 x 7 mm
Suitable for	Ribbon cable RM 1.27 mm
Plug direction.....	Perpendicular to the circuit board
Operating Temperature.....	-40 to +105 °C

