

PHILIPS



Lois Ultra Efficient

9290046428

9290046429

9290046430

9290046431



User manual
Benutzerhandbuch
Notice d'emploi
Manual de usuario
Manual do usuário
Manuale d'uso
Gebruiksaanwijzing

Incl.


A



B




1x

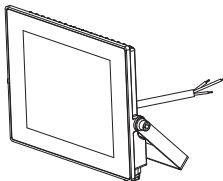

	SG (m ²)	
14W	0.0168m ²	0.5m
24W	0.0245m ²	0.5m

 Excl.







2x
Ø6x30mm
2x
ST4.2x29mm



14W	4mm
24W	5mm




    B








I0NC	W	VAC	Hz	Im	K	PF
9290046428	14	220-240V	50/60	2600	3000	> 0.5
9290046429	14			2650	5000	
9290046430	24			4450	3000	
9290046431	24			4500	5000	

mm


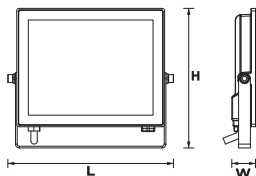


	L	H	W	Icon
14W 830 BK	158	145	28	0.370kg
14W 850 BK	158	145	28	0.370kg
24W 830 BK	196	165	28	0.530kg
24W 850 BK	196	165	28	0.530kg

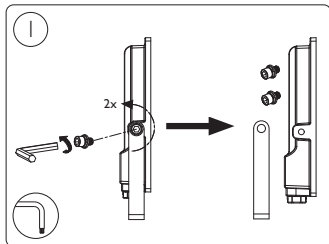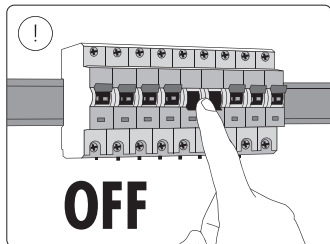


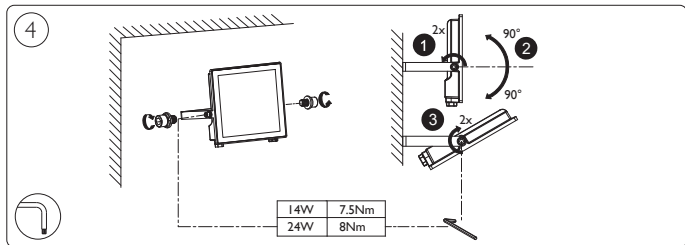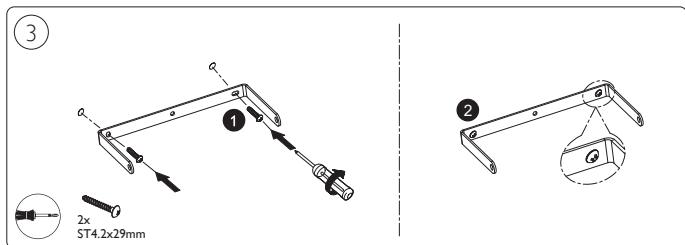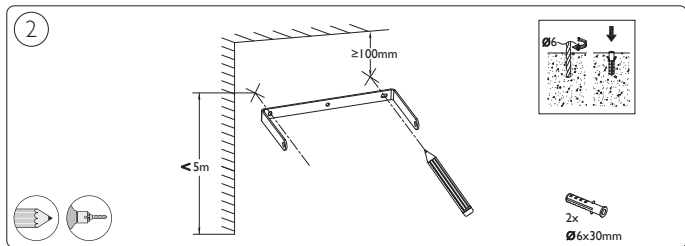


5

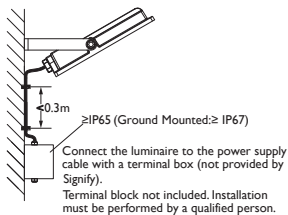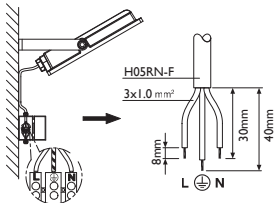

6

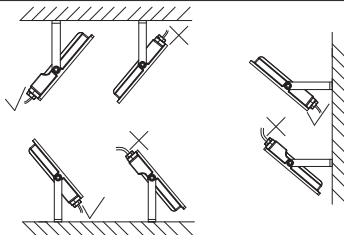

!

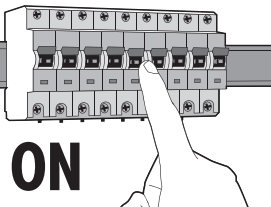



Signify Commercial UK Limited
Unit 3, Guildford Business Park,
Guildford, Surrey, GU2 8XG, UK

Signify
I.B.R.S. / C.C.R.I. Numéro 10461
5600 VB Eindhoven, the Netherlands
00800-74454775

Philips and the Philips Shield Emblem
are registered trademarks of Koninklijke
Philips N.V. and are used under license.

www.philips.com/lighting

© 2024 Signify Holding
Signify

3241 662 14371