

PHILIPS



Lois Ultra Efficient

9290046432

9290046433

9290046434


9290046435



User manual
Benutzerhandbuch
Notice d'emploi
Manual de usuario
Manual do usuário
Manuale d'uso
Gebruiksaanwijzing

Incl.

1x

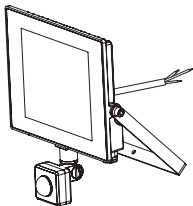

A




B



	S.Cx (m ²)	
14W	0.0189m ²	0.5m
24W	0.0266m ²	0.5m

 Excl.



2x
Ø6x30mm











2x
ST4.2x29mm






14W	4mm
24W	5mm







        B




IONC	W	VAC	Hz	Im	K	PF
9290046432	14	220-240V	50/60	2600	3000	> 0.5
9290046433	14			2650	5000	
9290046434	24			4450	3000	
9290046435	24			4500	5000	

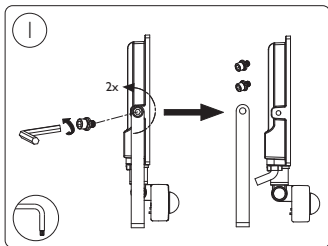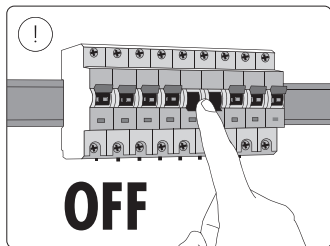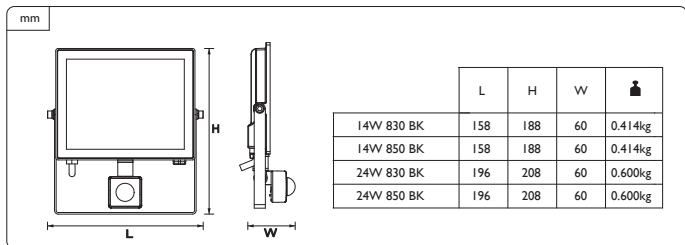


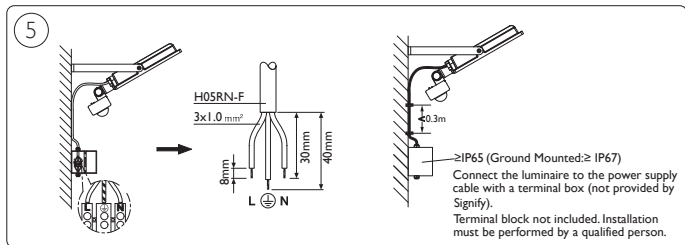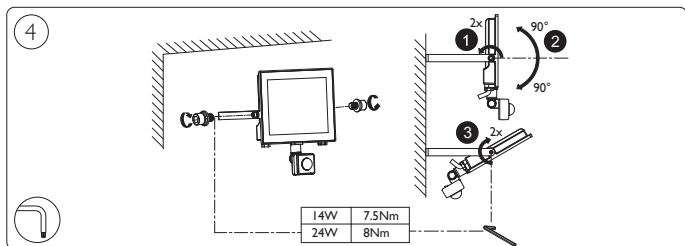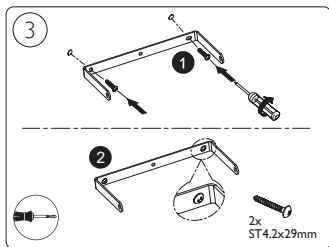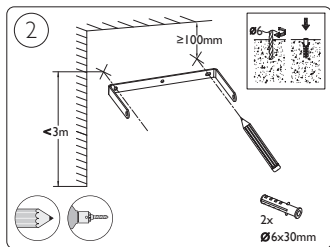


6

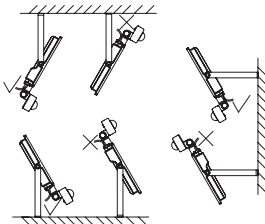





7

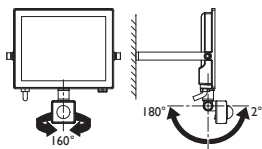

!

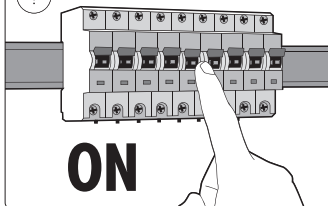

!

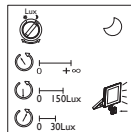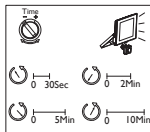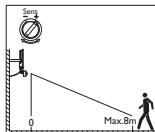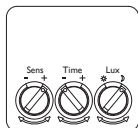



Signify Commercial UK Limited
Unit 3, Guildford Business Park,
Guildford, Surrey, GU2 8XG, UK

Signify
I.B.R.S. / C.C.R.I. Numéro 10461
5600 VB Eindhoven, the Netherlands
00800-74454775

Philips and the Philips Shield Emblem
are registered trademarks of Koninklijke
Philips N.V. and are used under license.

www.philips.com/lighting

© 2024 Signify Holding
Signify

3241 662 14381