


Hand tacker J-13

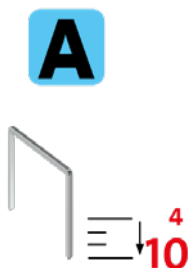

- The small hand tacker with high-quality aBs plastic housing for general-purpose use.
- Takes fine wire staples of 4 to 10 mm
- Takes hammer tacker staples H
- Lock down handle for storage when not in use
- Easily visible staple level
- Bottom-loading mechanism with safety lock release for quick reloading.
- Ergonomic soft-grip handle for working comfort
- For accurate results, the design line on the front of the tacker indicates exactly where the staples exit

Article number	030-0472
EAN Code	4009729082737
Loading capacity	150 x Fine wire staple A model 53 150 x Fine wire staple H model 37
processable materials	Fabrics/ txtiles/ upholstery Rugs soft plastic boards (2-10 mm)
Features	Lock-down handle staple inspection window Safety lock release Staple exit indicator Depth setting

Hand tacker J-13



Integrated staple slider for quick loading of staples. All parts form a single unit with no loose parts to lose.



Space-saving handle lock for safe storage when not in use



The open staple channel shows how many staples are left in the magazine.



Integrated staple slider for quick loading of staples. All parts form a single unit with no loose parts to lose.



Easily visible, coloured pictograms indicate which staples the tacker can process.



For accurate results, the design line on the front of the tacker indicates exactly where the staples exit