


Hand tacker J-15

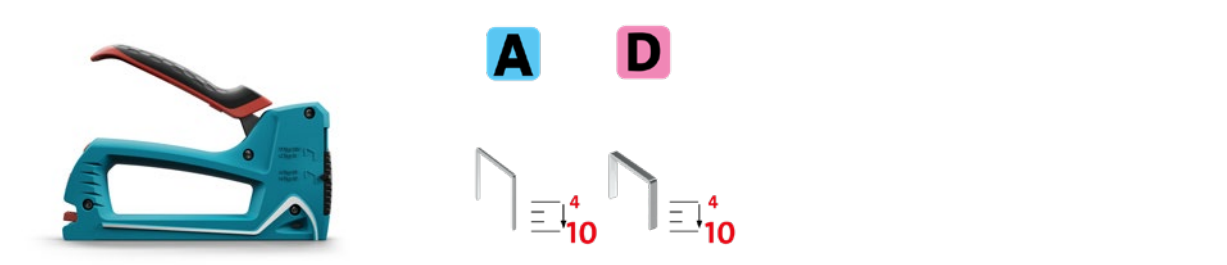

- The small universal tacker for interior finishing work and decoration.
 - Takes fine wire and flat wire staples of 4 to 10 mm
 - Takes hammer tacker staples H and G
 - Slide mechanism makes it easy to switch between fine wire staples and flat wire staples
 - Ergonomic soft-grip handle for working comfort
- Lock down handle for storage when not in use
 - Easily visible staple level
 - Bottom-loading mechanism with safety lock release for quick reloading.
 - For accurate results, the design line on the front of the tacker indicates exactly where the staples exit

Article number	030-0473
EAN Code	4009729082751
Loading capacity	150 x Fine wire staple A model 53 85 x Flat wire staple D model 53F 150 x Fine wire staple H model 37 85 x Flat wire staple G model 11
processable materials	Fabrics/ txtiles/ uphoulding Rugs soft plastic boards (2-10 mm) Leather/ faux leather Sheets Paper/ cardboard Waxed/ oiled papers Insulation mat (glass wool) Aluminium-laminated products Weather strip
Features	Lock-down handle staple inspection window Safety lock release Staple exit indicator Depth setting

Hand tacker J-15



The tacker can be easily adjusted for working with fine and/or flat wire staples using the slide mechanism on the front of the device.



Integrated staple slider for quick loading of staples. All parts form a single unit with no loose parts to lose.



The open staple channel shows how many staples are left in the magazine.



This tacker can hold 150 A type 53 or H type 37 fine wire staples, or 85 D type 53 F or G type 11 flat wire staples.



Space-saving handle lock for safe storage when not in use