

## Heating Cable 230 V

Item no: 3385620 (37.5 W, heating: 2.5 m)


Item no: 3385621 (75 W, heating: 5 m)

## Overview

### Technical data

#### Item No.: 3385620

|                                   |                                           |
|-----------------------------------|-------------------------------------------|
| Input .....                       | 230 V/AC 50-60 Hz                         |
| Output power .....                | 15 W/m, 37.5 W total                      |
| Ingress protection .....          | IPX7                                      |
| Cable bend radius .....           | ø3.5                                      |
| Cable .....                       | H05RN-F 3G 0.75 mm <sup>2</sup>           |
| Thermostat .....                  | Bimetal                                   |
| Thermal switching .....           | ON: <5 °C ±5 °C, OFF: >10 °C ±5 °C.       |
| Cable withstand temp. ....        | max. 70 °C                                |
| Operating/storage conditions..... | -20 to +45 °C , <90 % RH (non-condensing) |
| Weight .....                      | 310 g                                     |

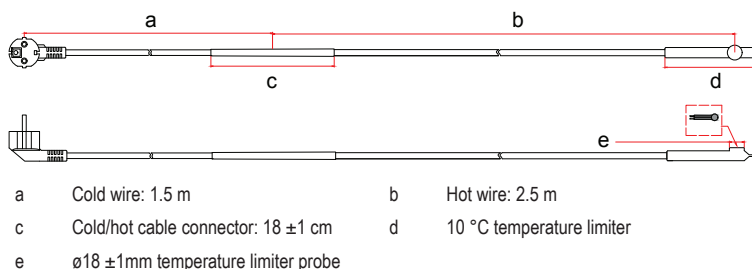

#### Item No.: 3385621

|                                   |                                           |
|-----------------------------------|-------------------------------------------|
| Input .....                       | 230 V/AC 50-60 Hz                         |
| Output power .....                | 15 W/m, 75 W total                        |
| Ingress protection .....          | IPX7                                      |
| Cable bend radius .....           | min. 3.5 cm                               |
| Cable .....                       | H05RN-F 3G 0.75 mm <sup>2</sup>           |
| Thermostat .....                  | Bimetal                                   |
| Thermal switching .....           | ON: <5 °C ±5 °C, OFF: >10 °C ±5 °C        |
| Cable withstand temp. ....        | max. 70 °C                                |
| Operating/storage conditions..... | -20 to +45 °C , <90 % RH (non-condensing) |
| Weight .....                      | 420 g                                     |

