


DATASHEET

USB-A 2.0 Receptacle (Female to Female)

Item No. 3385887

Overview

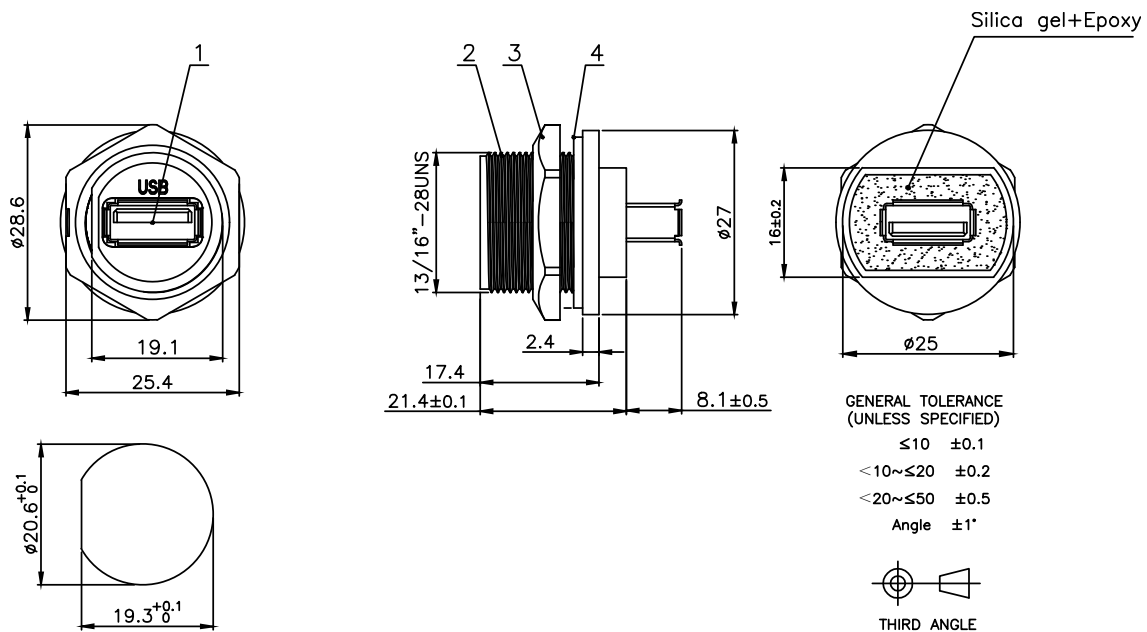

Technical data

Rated current.....	1.5 A
Rated voltage	5 V
Nominal voltage.....	30 V
Protection level.....	IP67
Temperature range	-25 to +80 °C
Insertion and removal times	≥ 500
Connection type.....	USB-A 2.0 cable
Connection A	USB 2.0 socket A
Connection B	USB 2.0 socket A
Contact material	Copper alloy
Housing material.....	PA

