


DATASHEET

USB-A 3.0 Receptacle (Female connector)

Item No. 3385894

Overview

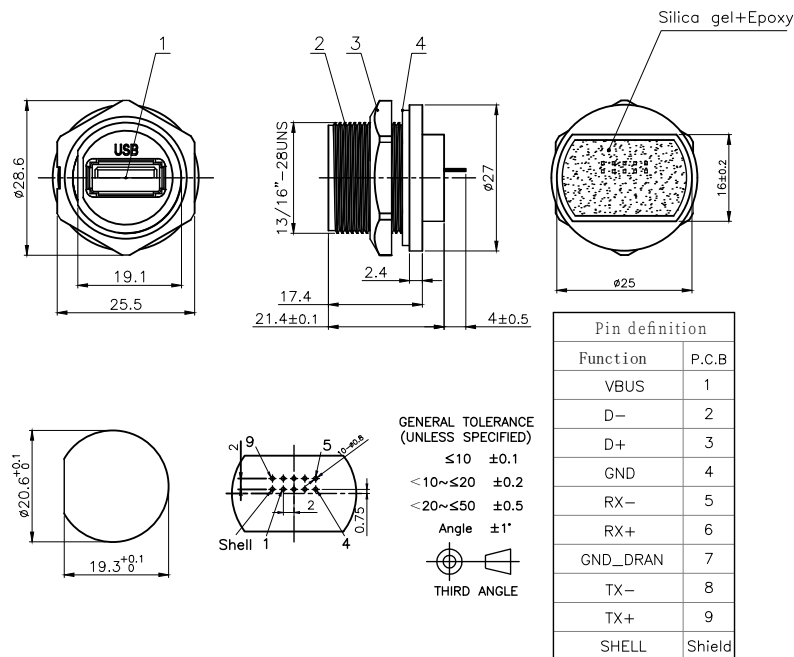

Technical data

Rated current.....	1.5 A
Rated voltage	5 V
Nominal voltage.....	30 V
Protection level.....	IP67
Temperature range	-25 to 80 °C
Insertion and removal times	≥500
Connection type.....	USB-A
Connection A	USB 3.0 socket A
Connection B.....	Pin header
Contact material	Copper alloy
Housing material.....	PA

