


DATASHEET

USB-C® 3.0 Receptacle (Female connector with wire)

Item No. 3385904

Overview

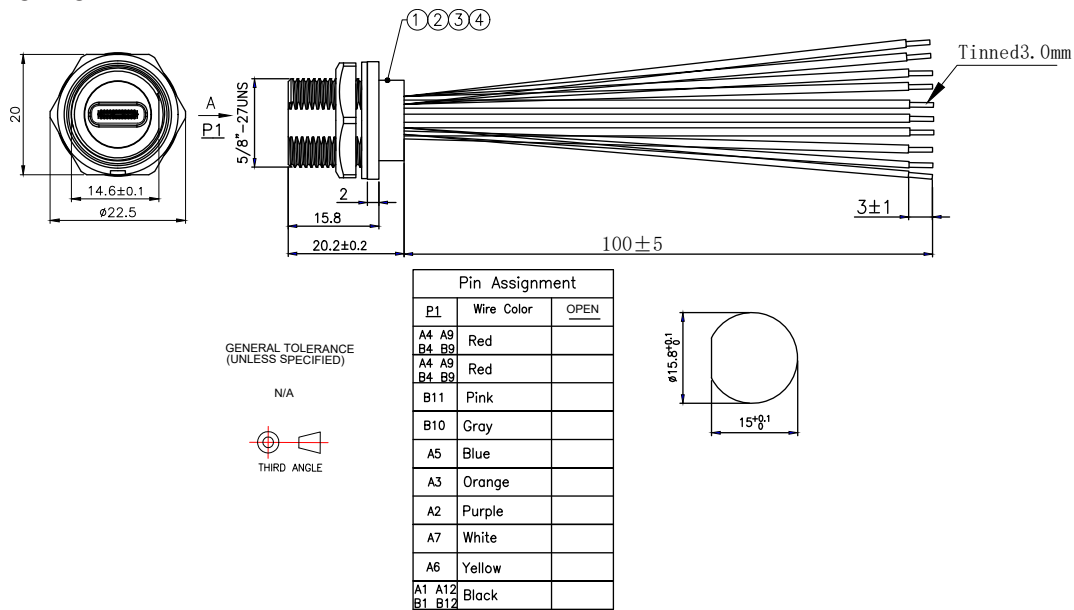

Technical data

Rated current.....	3 A
Rated voltage	20 V
Nominal voltage.....	30 V
Protection level	IP67
Temperature range	-25 to 80 °C
Insertion and removal times	≥500
Connection type.....	USB-C®
Connection A	USB-C® 3.0 socket
Connection B	USB-C® 3.0 socket
Cable diameter range	1.5 - 1.7 mm
Cable length	0.1 m
Contact material	Copper alloy
Housing material.....	PA

