


DATASHEET

RJ45 Cable CAT6A (Right-angle Male)

Item No. 3385910

Overview

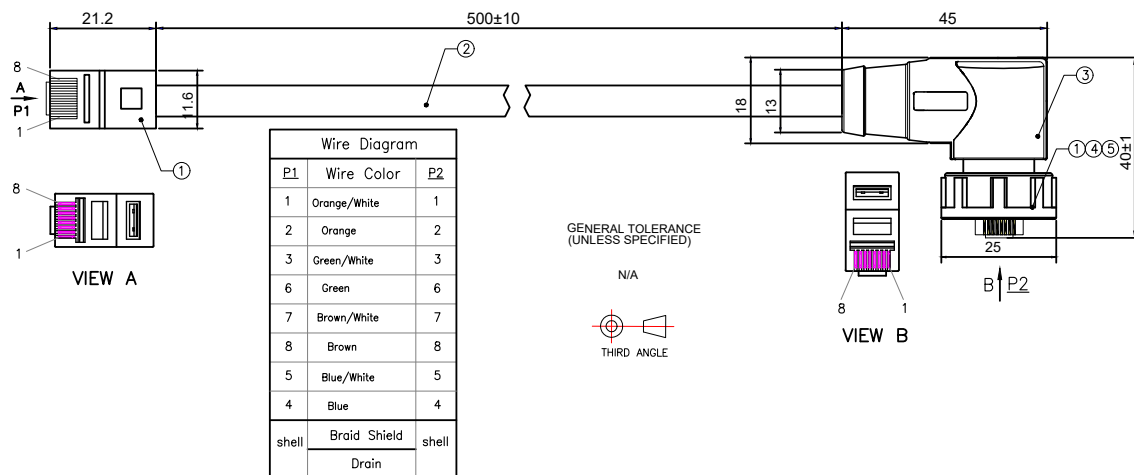

Technical data

Rated current	1.5 A
Rated voltage	48 V
Protection level	IP67
Temperature range	-25 to 80 °C
Insertion and removal times	≥500
Connection type	RJ45
Connection A	RJ45 connector
Connection B	RJ45 connector
Contact material	Copper alloy
Cable length	0.5 m

