


DATASHEET

RJ45 Receptacle CAT6A (Female to Female, 180°)

Item No. 3385914

Overview

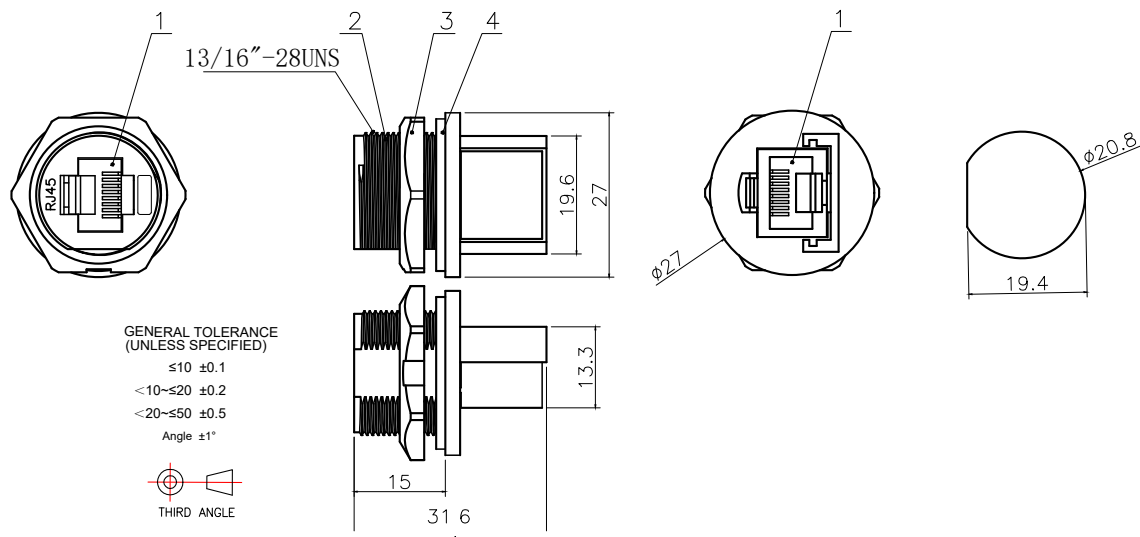

Technical data

Rated current.....	1.5 A
Rated voltage	48 V
Protection level	IP67
Temperature range	-25 to 80 °C
Insertion and removal times	≥ 500
Connection type.....	RJ45
Connection A	RJ45 socket
Connection B	RJ45 socket
Contact material	Copper alloy

