

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 1502070002
Status: Active
Overview: Ditto Wire-to-Wire Interconnects
Description: Ditto Wire-to-Wire Interconnects, Single-Ended Pigtail Harness, 2.50mm Pitch, 0.30m Length, 3 Circuits

Documents:
[Drawing \(PDF\)](#) [Test Summary TS-36876-001-001 \(PDF\)](#)
[Product Specification PS-36876-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Cable Assemblies
Series 150207
Application Power, Wire-to-Wire
Assembly Configuration Single Ended Connector
Connector to Connector Ditto-to-Pigtail
Overmolded No
Overview Ditto Wire-to-Wire Interconnects
Product Name Ditto
Type Discrete Wire Assembly
UPC 889056240925


Physical
Cable Length 0.30m
Circuits (Loaded) 3
Color - Resin White
Gender Hermaphroditic
Lock to Mating Part No
Material - Metal Copper Alloy
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 7.047/g
Number of Rows 1
Packaging Type Bag
Pitch - Mating Interface 2.50mm
Single Ended Yes
Wire Size AWG 20, 22, 24, 26
Wire/Cable Type UL 1061

Electrical
Current - Maximum per Contact 8.0A
Voltage - Maximum 350V AC

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number KAB2290L0.3V01

Reference - Drawing Numbers
Product Specification PS-36876-001-001
Sales Drawing SD-150207-0001
Test Summary TS-36876-001-001

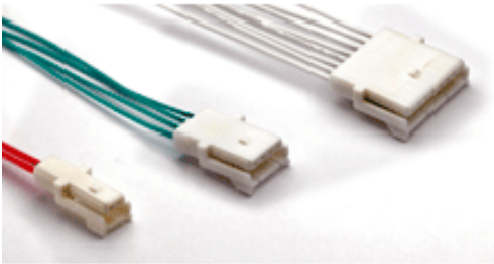

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/71/2019 (16 July
2019)
Halogen-Free
Status
Not Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
150207 Series

Mates With
36877 Ditto Hermaphroditic Crimp Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION