


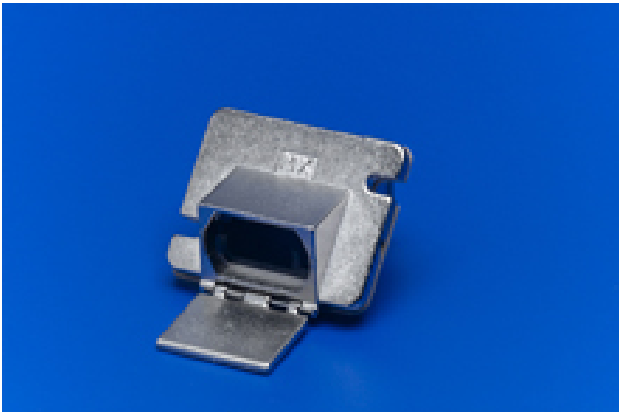

Part Number : [1061143000](#)
Product Description : EMI MPO Adapter,
Angled, Simplex, Metal Body, Screw Mount
Style, Shutter
Series Number : 106114
Status : Active
Product Category : Fiber Optic Adapters
Engineering Number : 861143000



Documents & Resources

Drawings
[1061143000_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Fiber Optic Adapters
Series	106114
Description	EMI MPO Adapter, Angled, Simplex, Metal Body, Screw Mount Style, Shutter
Component Type	EMI Shielding
Product Name	MPO
Type	Adapter
UPC	822350276825

Electrical

Shield Type	EMI Gasket
Shielded	Yes

Physical

Alignment Sleeve	N/A
Angled Physical Contact (APC)	N/A
Color - Resin	N/A
Gender	Female-Female
Material - Housing	Die-Cast
Mounting Style	Screws
Net Weight	13.744/g
Orientation	45° Angle
Panel Mount	With Flange
Ports	1
Shutter	One Side

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----
