

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0451320803

Status:


Active

Overview:

Micro-Fit Connector System

Description:

Micro-Fit TPA-to-Micro-Fit TPA Off-the-Shelf (OTS) Cable Assembly, Dual Row, 300.00mm Length, 8 Circuits, Black

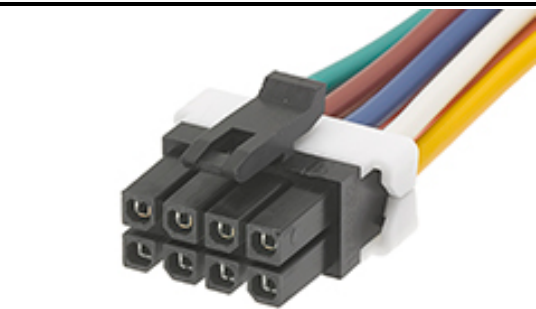

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	45132
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Micro-Fit TPA Both Ends
Overmolded	No
Overview	Micro-Fit Connector System
Product Literature Order No	987651-6143
Product Name	Micro-Fit TPA
Type	Discrete Wire Assembly
UPC	889056743785

Physical	
Cable Length	300.00mm
Circuits (Loaded)	8
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	21.736/g
Number of Rows	2
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.76mm
Wire Size AWG	20
Wire/Cable Type	UL 1007

Electrical	
Current - Maximum per Contact	5.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers	
Sales Drawing	2012341033-000

EU ELV

Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

45132 Series

Mates With

Micro-Fit 3.0 Headers [43045](#)
Micro-Fit 3.0 Plug Housings [43020](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION