



Part Number : [11260025](#)


Product Description : Hand Crimp Tool
JHTR2262J

Series Number : HTR2262J

Status : Obsolete

Product Category : Crimp Presses and Crimp
Hand Tools

Engineering Number : JHTR2262J

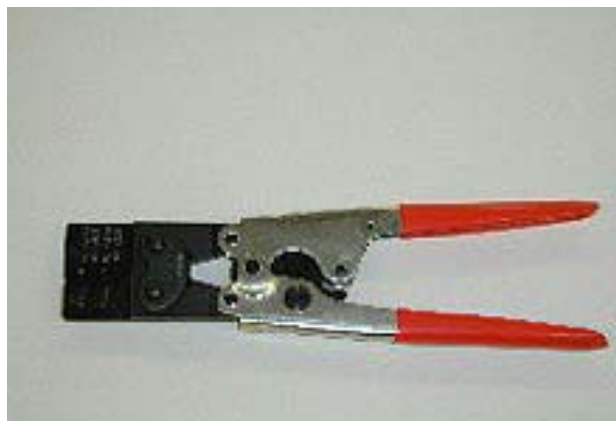

Documents & Resources

Tooling Specifications

[ATP-JHTR2262J-JE-001.pdf](#)

[ATP-JHTR2262J-E-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Product not active
China RoHS	Product not active
EU ELV	Product not active
Low-Halogen Status	Product not active
REACH SVHC	Product not active
EU RoHS	Product not active

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Obsolete
Category	Crimp Presses and Crimp Hand Tools
Series	HTR2262J
Description	Hand Crimp Tool JHTR2262J
Comments	Type: Japan
Function	Crimp
Geographic Area	Japan
Level of Automation	Manual
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	800753608535
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Applicable Parts

Description	Part Number
KK Cat Ear Crimp Terminal 5159, 28-22 AWG, Bag, Phosphor Bronze, Tin (Sn) Plating	<u>08700049</u>
KK Cat Ear Crimp Terminal 5159, 28-22 AWG, Bag, Brass, Tin (Sn) over Copper Plating	<u>08700069</u>

2.50mm Pitch Mini-Latch Crimp Terminal, Male, Brass, Bag	<u>08700103</u>
KK 254 Crimp Terminal, 28-22 AWG, 0.35µm Gold (Au), Nickel (Ni) Under-Plate, Brass, Loose	<u>39000377</u>
KK 254 Crimp Terminal, 28-22 AWG, 0.35µm Gold (Au), Nickel (Ni) Under-Plate, Phosphor Bronze, Loose	<u>39000381</u>

This document was generated on Feb 26, 2025