


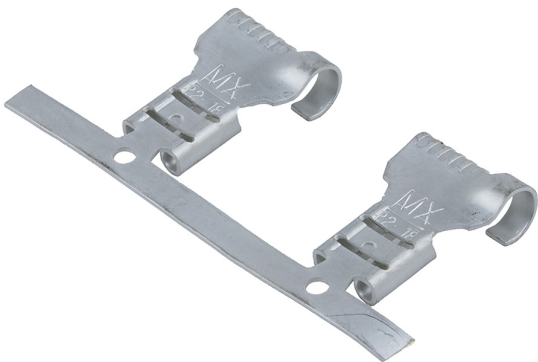

Part Number : [190090008](#)
Product Description : VibraKrimp Quick Disconnect Flag, Female, for 22-18 AWG Wire, Metal Strip Carrier
Series Number : 19009
Status : Active
Product Category : Quick Disconnects
Engineering Number : AAZ-4170



Documents & Resources

Drawings

[190090008_sd.pdf](#)
[PK-19009-001-001.pdf](#)

3D Models and Design Files

[190090008_stp.zip](#)

Specifications

[PS-19902-005-001.pdf](#)
[PS-19902-011-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Quick Disconnects
Series	19009
Description	VibraKrimp Quick Disconnect Flag, Female, for 22-18 AWG Wire, Metal Strip Carrier
Comments	Wire Grip
Product Name	VibraKrimp
Type	Quick Disconnect
UPC	800755046861

Agency

CSA	LR18689
UL	E79133

Electrical

Voltage - Maximum	Per Wire Specification
-------------------	------------------------

Physical

Barrel Type	Closed
Gender	Female
Glow-Wire Capable	No
Insulated	No
Insulation	None
Lock to Mating Part	None

Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.800/g
Orientation	Flag
Packaging Type	Reel
Polarized to Mating Part	No
Tab Thickness	0.51mm
Tab Width	4.75mm
Temperature Range - Operating	Per Wire Specification
Wire Insulation Diameter	3.43mm max.
Wire Size (AWG)	18, 20, 22

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
Mini-Mac Applicator Rear Feed	<u>638027400</u>