


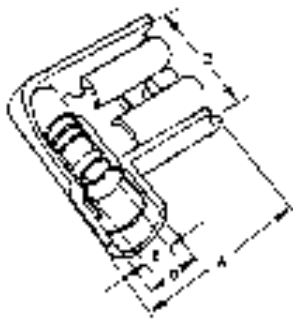

Part Number : [190070084](#)
Product Description : InsulKrimp Female Fully Insulated Quick Disconnect Flag for 12-10 AWG Wire, Tab 6.35 x 0.81mm, 94 V-0 Material, Metal Strip
Series Number : 19007
Status : Active
Product Category : Quick Disconnects
Engineering Number : C-2211VZ



Documents & Resources

Drawings

[190070084_sd.pdf](#)
[PK-19007-001-001.pdf](#)

3D Models and Design Files

[190070084_stp.zip](#)

Specifications

[PS-19902-008-001.pdf](#)
[PS-19902-011-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Quick Disconnects
Series	19007
Description	InsulKrimp Female Fully Insulated Quick Disconnect Flag for 12-10 AWG Wire, Tab 6.35 x 0.81mm, 94 V-0 Material, Metal Strip
Product Name	InsulKrimp
Type	Quick Disconnect
UPC	800756387062

Agency

UL	E79133
----	--------

Electrical

Voltage - Maximum	600V
-------------------	------

Physical

Barrel Type	Closed
Color - Resin	Yellow
Flammability	94V-0
Gender	Female
Glow-Wire Capable	Yes
Insulated	Fully
Insulation	Nylon (PA)

Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	1.599/g
Orientation	Flag
Packaging Type	Reel
Polarized to Mating Part	No
Tab Thickness	0.81mm
Tab Width	6.35mm
Temperature Range - Operating	-65° to +105°C
Wire Insulation Diameter	6.60mm
Wire Size (AWG)	10 (105 strands), 12 (65 strands)