




Part Number : [191290020](#)  
Product Description : Krimptite Block Spade  
Terminal for 16-14 AWG Wire  
Series Number : 19129  
Status : Active  
Product Category : Ring and Spade Terminals  
Engineering Number : BB-1781-10

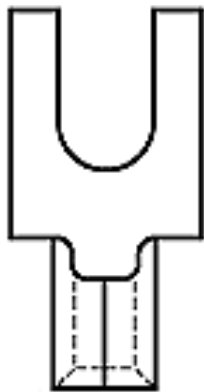

## Documents & Resources

Drawings  
[191290020\\_sd.pdf](#)

3D Models and Design Files  
[191290020\\_stp.zip](#)

Specifications  
[PS-19902-011-001.pdf](#)  
[PS-19902-013-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                                                        |
| REACH SVHC         | Not Contained per D(2024)6225-DC (07 Nov 2024)                                        |
| EU RoHS            | Compliant per EU 2015/863                                                             |

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|              |                                                   |
|--------------|---------------------------------------------------|
| Status       | Active                                            |
| Category     | Ring and Spade Terminals                          |
| Series       | 19129                                             |
| Description  | Krimptite Block Spade Terminal for 16-14 AWG Wire |
| Keyword      | Spade Terminal, Spade Terminals                   |
| Product Name | Krimptite                                         |
| Type         | Spade Block                                       |
| UPC          | 800755083828                                      |

#### Agency

|     |         |
|-----|---------|
| CSA | LR18689 |
| UL  | E32244  |

#### Physical

|                             |                      |
|-----------------------------|----------------------|
| Barrel Type                 | Closed               |
| Insulation                  | None                 |
| Material - Plating Mating   | Tin                  |
| Net Weight                  | 0.617/g              |
| Packaging Type              | Bag                  |
| Plating min - Mating        | 2.540µm              |
| Plating min - Termination   | 2.540µm              |
| Stud Size                   | 10 (M5)              |
| Termination Interface Style | Crimp or Compression |
| Wire Size (AWG)             | 14, 16               |
| Wire Size mm <sup>2</sup>   | 1.30-2.00            |

---

Application Tooling

Global

| Description                                                                                                                        | Part Number      |
|------------------------------------------------------------------------------------------------------------------------------------|------------------|
| PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 22-10 AWG and 6.0mm <sup>2</sup> - 0.5mm <sup>2</sup> | <u>640030100</u> |
| Crimp Head for the AT-200 Pneumatic Hand Tool                                                                                      | <u>640070100</u> |
| ServiceGrade Hand Crimp Tool - Ratchet                                                                                             | <u>640160038</u> |