


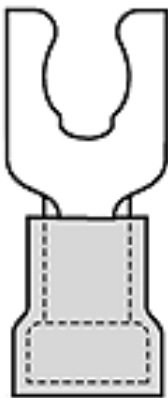

Part Number : [191150025](#)
Product Description : Avikrimp Snap Spade
Terminal for 16-14 AWG Wire
Series Number : 19115
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : BB-8707-06T



Documents & Resources

Drawings
[191150025_sd.pdf](#)

3D Models and Design Files
[191150025_stp.zip](#)

Specifications
[PS-19902-011-001.pdf](#)
[PS-19902-015-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)
- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19115
Description	Avikrimp Snap Spade Terminal for 16-14 AWG Wire
Keyword	Spade Terminal, Spade Terminals
Product Name	Avikrimp
Type	Spade Snap
UPC	800753092136

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.918/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	6 (M3.5)
Wire Insulation Diameter	4.30mm max.
Wire Size (AWG)	14, 16

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>192880123</u>
Mini-Mac Applicator	<u>638850400</u>