


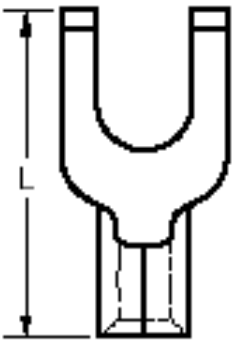

Part Number : [191180088](#)
Product Description : Krimptite Flanged Spade
Tongue Terminal for 12-10 AWG Wire, Stud
Size 10 (M5), Length 19.56mm
Series Number : 19118
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : C-117-10



Documents & Resources

Drawings
[191180088_sd.pdf](#)

3D Models and Design Files
[191180088_stp.zip](#)

Specifications
[PS-19902-011-001.pdf](#)
[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19118
Description	Krimptite Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Length 19.56mm
Keyword	Spade Terminal, Spade Terminals
Product Name	Krimptite
Type	Spade
UPC	800755082821

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	1.470/g
Packaging Type	Bag
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	10 (M5)
Wire Size (AWG)	10, 12
Wire Size mm ²	4.00-6.00

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 22-10 AWG and 6.0mm ² - 0.5mm ²	<u>640030100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640070100</u>
ServiceGrade Hand Crimp Tool - Ratchet	<u>640160038</u>