




**Part Number :** [190330005](#)  
**Product Description :** Krimptite Snap Plug, for 16-14 AWG Wire  
**Series Number :** 19033  
**Status :** Active  
**Product Category :** Quick Disconnects  
**Engineering Number :** B-179

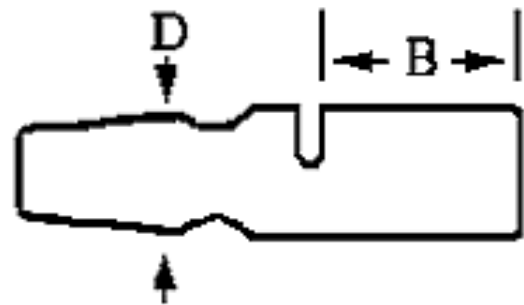

## Documents & Resources

**Drawings**  
[190330005\\_sd.pdf](#)

**3D Models and Design Files**  
[190330005\\_stp.zip](#)

**Specifications**  
[PS-19902-011-001.pdf](#)  
[PS-19902-013-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                |
|--------------------|------------------------------------------------|
| GADSL/IMDS         | Compliant with Exemption 44                    |
| China RoHS         |                                                |
| EU ELV             | Not Relevant                                   |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                 |
| REACH SVHC         | Not Contained per D(2024)6225-DC (07 Nov 2024) |
| EU RoHS            | Compliant per EU 2015/863                      |

Multiple Part Product Compliance Statements  
- Eu RoHS  
- REACH SVHC  
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|              |                                         |
|--------------|-----------------------------------------|
| Status       | Active                                  |
| Category     | Quick Disconnects                       |
| Series       | 19033                                   |
| Description  | Krimptite Snap Plug, for 16-14 AWG Wire |
| Product Name | Krimptite                               |
| Type         | Snap Plug                               |
| UPC          | 800755058987                            |

#### Agency

|     |         |
|-----|---------|
| CSA | LR18689 |
| UL  | E152602 |

#### Electrical

|                   |     |
|-------------------|-----|
| Voltage - Maximum | N/A |
|-------------------|-----|

#### Physical

|                                |        |
|--------------------------------|--------|
| Barrel Type                    | Closed |
| Gender                         | Male   |
| Glow-Wire Capable              | No     |
| Insulated                      | No     |
| Insulation                     | None   |
| Lock to Mating Part            | None   |
| Material - Metal               | Brass  |
| Material - Plating Mating      | Tin    |
| Material - Plating Termination | Tin    |

|                             |                      |
|-----------------------------|----------------------|
| Net Weight                  | 1.397/g              |
| Orientation                 | Straight             |
| Packaging Type              | Bag                  |
| Tab Thickness               | N/A                  |
| Tab Width                   | N/A                  |
| Termination Interface Style | Crimp or Compression |
| Wire Insulation Diameter    | N/A                  |
| Wire Size (AWG)             | 14, 16               |
| Wire Size mm <sup>2</sup>   | 1.30-2.00            |

---

## Application Tooling

### Global

| Description                                                                                                                        | Part Number      |
|------------------------------------------------------------------------------------------------------------------------------------|------------------|
| PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 22-10 AWG and 6.0mm <sup>2</sup> - 0.5mm <sup>2</sup> | <u>640030100</u> |
| Crimp Head for the AT-200 Pneumatic Hand Tool                                                                                      | <u>640070100</u> |
| ServiceGrade Hand Crimp Tool - Ratchet                                                                                             | <u>640160038</u> |