


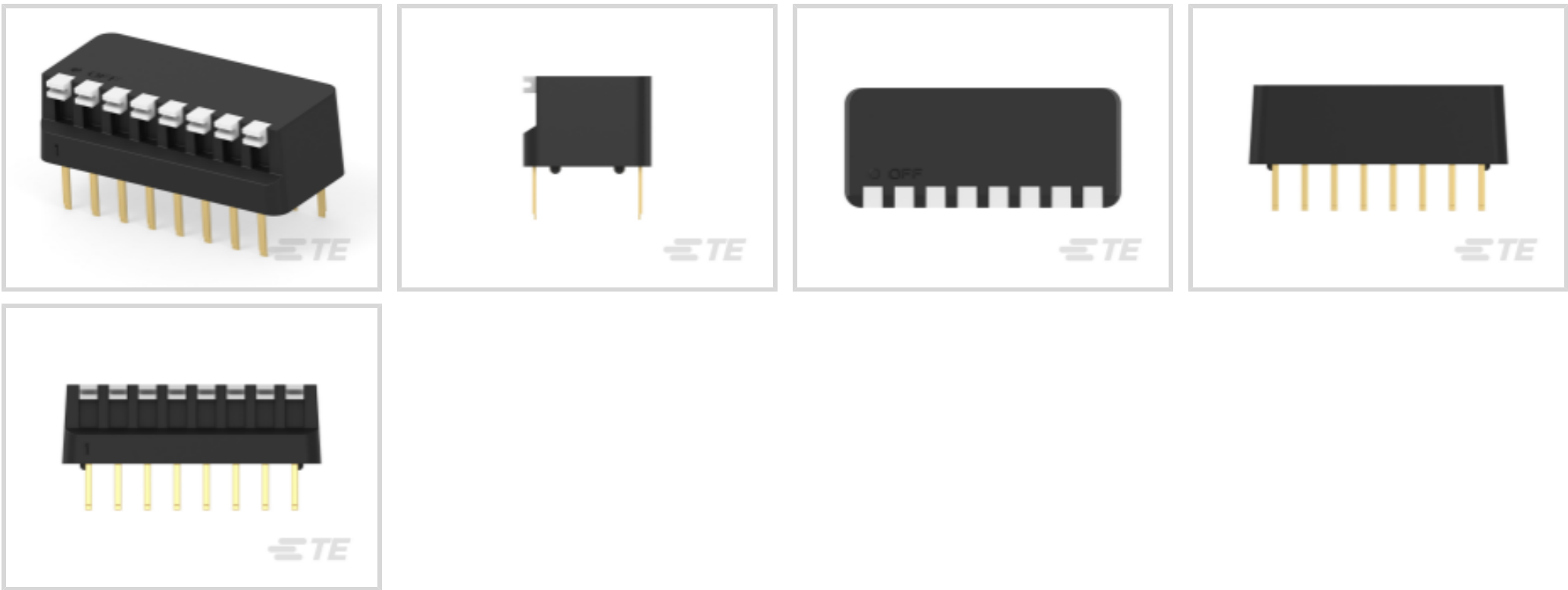

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JAN 2023 (233) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 5435640-5
DIP SW 8POSN AU



TE Part # 4-5435640-1
DIP SW 10 POSN SEALED



TE Part # 5161390-1
01P.DIP SWITCH ASSY



TE Part # 1977104-4
STV08=8 POS SIP SWITCH



TE Part # 3-5435640-9
DIP SW 8 POSN SEALED

Customers Also Bought



TE Part #794703-1
CMNL SOCKET R/A



TE Part #1-770178-0
06P MINI-UMNL ASSY VO SNNI*



TE Part #3-5353652-6
.5FHP08H,440,B,GIG,08/Sn,HT,NSYes



TE Part #3-641215-4
04P MTA100 HDR ASSY FL/ST 30AU



TE Part #8-1879501-5
CRGH2512 5% 3K3 2W



TE Part #4-1879354-6
RR03 5% 24R AMMO




TE Part #6-1879207-0
RN 0603 412K 0.1% 10PPM 5K RL



TE Part #1-1571983-0
GDH08S04=DIP SWITCH



TE Part #1676435-2
RN 0805 7K15 0.1% 10PPM 1KRL

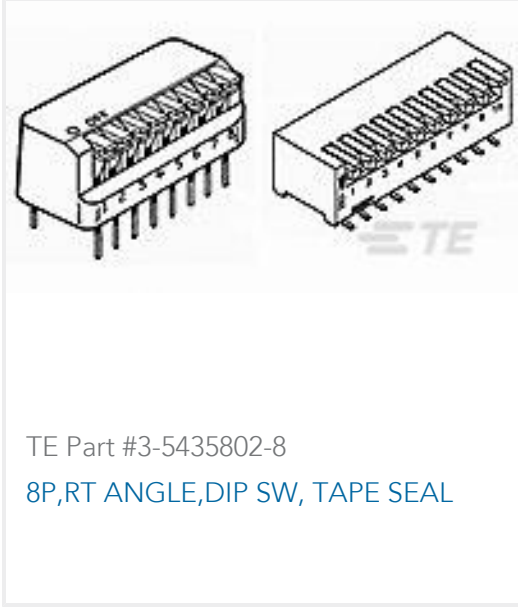

TE Part #3-5435802-8
8P,RT ANGLE,DIP SW, TAPE SEAL

Documents



Product Drawings

RIGHT ANGLE DIP SW 8 P SEALED

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5435802-9_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5435802-9_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5435802-9_C.3d_stp.zip

English

3D PDF

English

Customer View Model

ENG_CVM_5435802-9_B.3d_igs.zip

English

Customer View Model

ENG_CVM_5435802-9_B.3d_stp.zip

English

Customer View Model

ENG_CVM_5435802-9_B.2d_dxf.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English