




HandyLaser Plus

Universal laser spirit level with 90° beam splitter - recycled material is used for sustainability



The universal laser spirit level enables precise horizontal alignment in many applications, such as in laying tiles, joinery, drywall and window fitting. The measuring tool has a point laser for optical extension which can also be used for vertical levelling by redirecting the beam using a beam splitter. Angles can also be created easily using the manual slope function. The special spring clips mean this laser spirit level is particularly useful when laying tiles. The magnetic bracket offers the benefit of hands-free working on metal constructions. The impact-proof, plastic housing is made from a large proportion of recycled material and makes a valuable contribution to sustainability.

- Sustainable design: large proportion of the housing is made from recycled plastic
- Exact horizontal alignment
- Integrated dot laser for optical extension
- Vertical levelling by deflecting the laser line through 90° with a beam splitter
- Manual alignment of slopes
- Special spring clips, ideal for tiling
- Free hands when working on metal constructions thanks to magnetic holder

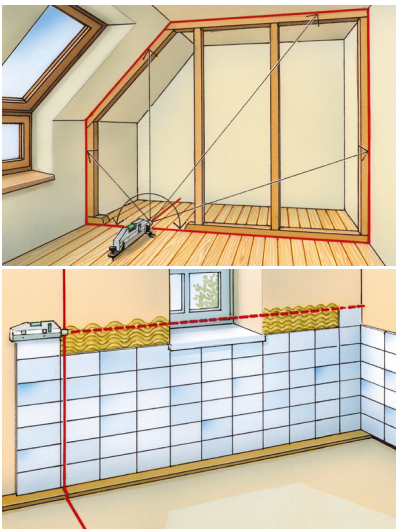

TECHNICAL DATA

Vial Accuracy	± 0.5 mm / m
Levelling	manual
Visibility (Typical)*	50 m
Laser Wavelength	650 nm
Laser Class	2 / < 1 mW (EN 60825-1:2014/ A11:2021 / EN 50689:2021)
Power Supply	2 x 1.5V LR03 (AAA)
Operating Time	approx. 65 hours
Operating Conditions	0°C ... 50°C, max. humidity 80% rH, no condensation, max. working altitude 4000 m above sea level
Storage Conditions	-10°C ... 70°C, max. humidity 80% rH
Dimensions (W x H x D)	210 mm x 59 mm x 62 mm
Weight	130 g (incl. batteries)

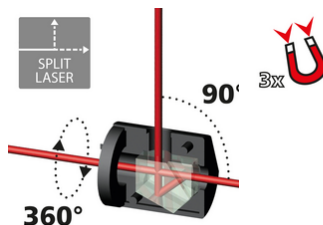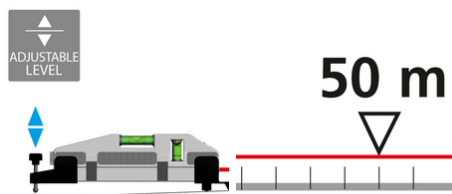

SCOPE OF DELIVERY

