



DigiLevel Plus 25

Digital electronic spirit levels: precise and easy to use


This digital spirit level provides accurate horizontal and vertical alignment as well as transfer of angles. Easy to use due to flip display and acoustic guidance. The magnetic bracket offers the benefit of hands-free working on metal constructions. High measuring accuracy is available due to the calibration function. The units of measurement can be selected on the device which also has milled measuring surfaces.

- Precise horizontal and vertical angle display
- Reference function for transferring angles
- Acoustic guidance with 3 different signal tones
- Comfortable overhead measurements thanks to flip display
- Calibration: permanent accuracy via reverse measurement
- Free hands when working on metal constructions thanks to magnetic holder
- Measurement units can be switched
- Easy-to-read display
- Vertical and horizontal vial
- Milled measuring surfaces



TECHNICAL DATA

Vial Accuracy	± 1 mm / m
Electronic Measuring Precision	± 0.1° at 0° ... 1° ± 0.1° at 89° ... 90° ± 0.2° at 1° ... 89°
Measurement Range Angle Measurement	360°
Display Accuracy	1 decimal place
Display Accuracy 0° - 1°	1 decimal place
Display Accuracy 1° - 90°	1 decimal place
Power Supply	2 x 1.5V LR03 (AAA)
Operating Conditions	0°C ... 50°C, max. humidity 80% rH, no condensation, max. working altitude 2000 m above sea level
Storage Conditions	-20°C ... 70°C, max. humidity 80% rH
Dimensions (W x H x D)	240 mm x 66 mm x 30 mm
Weight	315 g (incl. batteries)

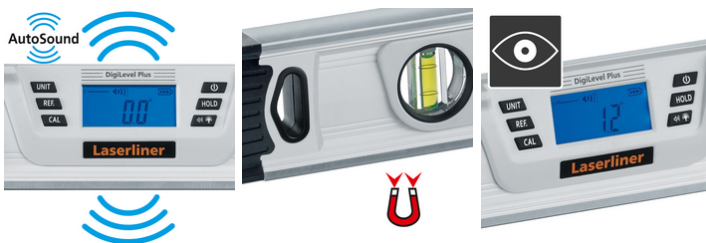

SCOPE OF DELIVERY

