



## VideoScope One

 

Compact inspection camera for visual inspections of areas which are difficult to access - recycled material is used for sustainability

This compact video inspection system with waterproof camera head is suitable for easy visual inspection of hard-to-reach places in pipes, cavities, shafts, masonry and motor vehicles. Illumination with four high-performance LEDs provides clear pictures, even in extremely poor light. The image always remains clear on the monitor through rotation and mirroring. The high-contrast LC display also provides an optimum image, even in bright light. The housing is largely made of recycled material, making a valuable contribution to sustainability.

- Sustainable design: large proportion of the housing is made from recycled plastic
- Easy problem localisation behind or in objects, walls, pipes, cavities
- Small camera head, ideal for places that are hard to reach
- Clear images even under the worst conditions
- Waterproof camera head and cable for use in sanitary areas
- Resistant to petrol and diesel
- Good object lighting due to 4 high-performance LEDs
- Image clearly discernible through rotation and mirroring
- Easy-to-read LC display

### TECHNICAL DATA

|                               |                                                      |
|-------------------------------|------------------------------------------------------|
| <b>Diameter Camera Head</b>   | 9 mm                                                 |
| <b>Camera Resolution</b>      | 320 x 240 pixels                                     |
| <b>Field of View (FOV)</b>    | 53°                                                  |
| <b>Depth of Focus (DOF)</b>   | 3 ... 7 cm                                           |
| <b>Screen Type</b>            | 2,7"                                                 |
| <b>Display Resolution</b>     | 320 x 240 pixels                                     |
| <b>Length of Probe</b>        | 1.5 m                                                |
| <b>Illumination</b>           | 5 brightness levels                                  |
| <b>Digital Zoom</b>           | 2x digital zoom in 20% increments                    |
| <b>Ports</b>                  | RCA video output                                     |
| <b>Power Supply</b>           | 4 x 1.5V LR6 (AA)                                    |
| <b>Dimensions (W x H x D)</b> | 100 mm x 200 mm x 130 mm x (without flexible tubing) |
| <b>Weight</b>                 | 510 g (incl. batteries)                              |

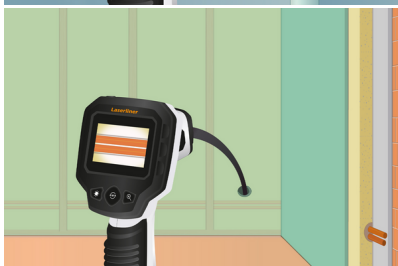

### SCOPE OF DELIVERY

