


VideoPocket

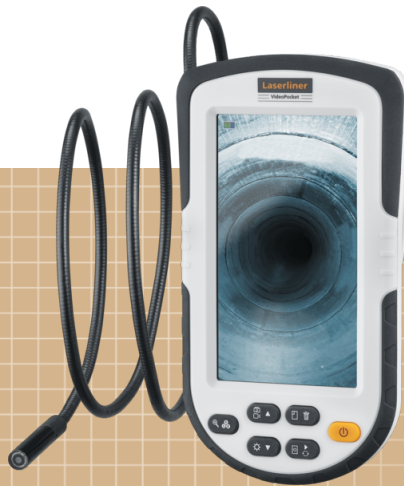

Compact video inspection system with large display with optimum legibility, compare image function, waterproof camera unit and practical mirror, magnet and hook attachments - recycled material for sustainability

This compact video inspection system allows easy visual inspection of hard-to-reach locations such as pipework, suspended ceilings and vehicles. Six powerful LEDs on the waterproof camera unit, adjustable in ten settings, ensure effective illumination of the object during use. Details can be clearly captured using the zoom function. Inspection results are clearly identifiable thanks to the large colour display and image alignment. The compare image function allows the user to see the differences between the live image and a saved reference image. The housing is largely made of recycled material and makes a valuable contribution to sustainability




- Sustainable design: large proportion of the housing is made from recycled plastic
- Effective problem localisation behind or in objects, walls, pipes, cavities
- Identify specific differences with the compare image function
- Powerful object lighting thanks to six high-performance LEDs
- Large, exceptionally easy-to-read display
- Suitable image available on the monitor through rotation and mirroring
- Waterproof and dustproof camera unit

TECHNICAL DATA

Diameter Camera Head	8 mm
Camera Resolution	640 x 480 pixels
Field of View (FOV)	65°
Depth of Focus (DOF)	3 ... 8 cm
Screen Type	4,3"
Display Resolution	480 x 272 pixels
Image Format	JPEG
Length of Probe	1 m
Illumination	10 brightness levels
Digital Zoom	2x digital zoom in 25% increments
Memory	Micro-SD memory card up to 32 GB
Port	Micro USB
Ports	Micro USB
Power Supply	4 x 1.5V LR6 (AA)
Dimensions (W x H x D)	85 mm x 155 mm x 32 mm
Weight	366 g (incl. batteries)



Image rotation 180°

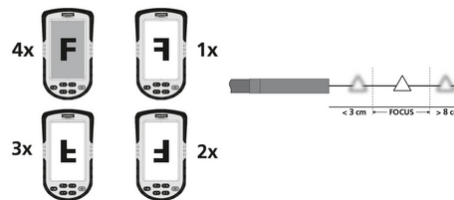

SCOPE OF DELIVERY



Item No. 082.261E GTIN (EAN) 4021563735174 SU 2