


NIIMBOT

Product Manual

Smart Label Printer

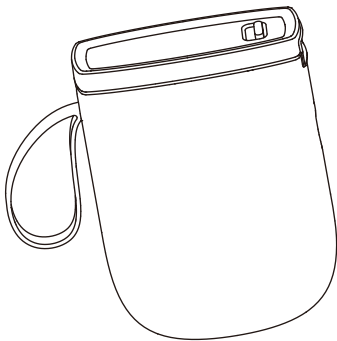

NIIMBOT D11

01

Package Contents



 
Smart Label Printer *1



Label Paper Roll *1




USB Type-C Cable *1




Product Manual *1

02


Installation

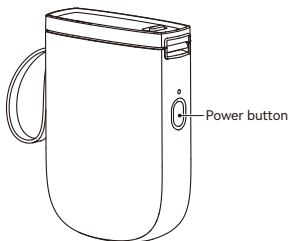

 - 1 Press and hold the power button for three seconds to power on.



- 2 Slide the door-open button to the left to open the paper compartment.

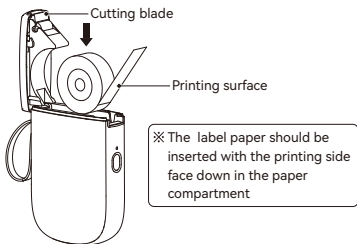

- 3 Place the label paper in the paper compartment with the print side down and the first label protruding from the paper outlet. Then close the paper compartment.

03

Printer Software

03-1 Recommended App Downloads

NIIMBOT APP Commercial Label Editing Expert

If you have purchased this product primarily for commercial or industrial applications, we recommend downloading the NIIMBOT app, which features a wide range of industry-specific label templates, data import capabilities, and batch printing functions.

You can download the app directly from the Google Play or Apple App Store.



NIIMBOT
Design & Print APP
easy to download and use



NIIM APP Your Home Labeling Assistant

If you have purchased this product mainly for home storage or personal creative projects, we recommend downloading and using the NIIM app, which features a variety of fun and creative icons and label templates for household use.

You can download the app directly from the Google Play or Apple App Store.



NIIM
Design & Print APP
easy to download and use



04

Connecting to Print

- 1 Once the app has downloaded, make sure your phone's Bluetooth is turned on.
- ※ Note: Location permissions may need to be enabled on Android phones.



Turn on Bluetooth ☒


- 2 Open the app and search for Bluetooth devices to connect to.
- ※ Note: If it asks for a PIN, enter 0000 or 1234 then press OK.
- 3 Once successfully connected, go to the Drawing Board.

Note

The illustrations of products, accessories, software interfaces, etc. in this getting started guide are illustrative in nature and for reference only. Due to product updates and upgrades, the physical product may differ slightly from the illustrations. Please refer to the actual physical product in such case. The product is subject to technical improvements without notice.

05

Product Description

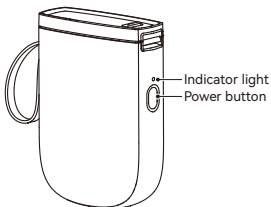


Button functions

Operation	Function description
Press and hold for 2–3 seconds	On or off
Quick press	This action can be set to "Don't feed paper," "Print current time" or "Print history" through the app.
Press twice	Print testing page

Indicator Light

Color	Status	Description
Blue	Solid	Powered on but not connected
	Flashing quickly	Upgrading firmware
Green	Solid	Bluetooth connected
	Flashing quickly	Printing
Red	Solid	Device fault

 

Power Indicator light

Power Indicator Light

Color	Status	Description
White	Blinking Slowly	Charging
	Solid	Fully charged and connected to power
	Flashing quickly	Low battery

06

Specifications

Product	Label Printer	Model	NIIMBOT D11_H
Dimensions	109*78*30mm	Weight	199g
Charging Time	1 - 2 hours	Input	5V DC, 2A
Battery Capacity	1500mAh	Printing Method	Thermal printing
Printing Resolution	300dpi	Printing Width	12mm
Connectivity	Bluetooth	Charge	Type-C
Transmit Power	4dBm(Maximum)	Operating Temperature	5°C - 40°C
Bluetooth	2402-2480MHz	BLE	2402-2480MHz
NFC	13.56MHz		

07

Safety Precautions

Read all instructions and warnings in this guide carefully before using the product to ensure proper and safe use of the product and to avoid personal injury or damage to property.

*Warnings



Do not disassemble the product yourself. No returns or exchanges will be authorized for disassembled products.



Do not use corrosive chemical products or cleaners to wipe down the product.



Do not use the product in the vicinity of flammable substances such as in gas stations, fuel depots, etc.

1. Keep the product and accessories in a safe place that is inaccessible to children, or only allow use under the supervision of a guardian.
2. Immediately disconnect the product from the power source if the product enters water.
3. Immediately disconnect the product if the device malfunctions.

4. If you use a power adapter to charge (or power) the device, you must purchase an adapter that is safe, compliant, and meets the standards.
5. Do not disassemble the product to replace the battery yourself. Incorrectly replacing the battery can result in an explosion.
6. The battery contains special protective circuitry and devices. Do not disassemble the battery as this may cause short circuits or electrolyte leakage. If electrolytes accidentally enter your eye, rinse immediately with clean water and seek medical advice.
7. Do not expose the appliance or power adapter to high-temperature or high-humidity environments, or put in water, to prevent short circuits that can cause the battery to become hot, smoke, deform, get damaged or even explode.
8. Disconnect the power adapter immediately if you notice either smoke or a smell coming from the product or the power adapter, taking care to avoid burns.

***Important**

Please purchase the version of the product that matches your region or country of use through the NIIMBOT official store or a NIIMBOT authorized sales agent. Purchasing the product through other channels may mean you buy a pirated product or a product not adapted to your region or country of use which may lead to usage issues. In such cases, NIIMBOT may be unable to provide you with further assistance.

Notice: If the device cannot be turned on, please charge for one hour.

Wuhan Jingchen Intelligent Identification Technology Co., Ltd.

Support Email : service@niimbot.com

Official Website : www.niimbot.com

Manufacturer's Address : No. 5, Creative Workshop, Creative World, Yezhihu West Road, Hongshan District, Wuhan, China

© 2024 NIIMBOT. All Rights Reserved.

NIIMBOT is a brand under Wuhan Jingchen Intelligent Identification Technology Ltd.