

DATASHEET

Rocker switch





Item No. 3399882 (Red)

Item No. 3399883 (Green)


Overview

Technical data

Protection class	IP65 (front)
Casing / button colour	Item No. 3399882: Black / Red Item No. 3399883: Black / Green
Function	Latch
Switch	DPST
Bulb type	Glow lamp
Switch position	2 x Off/On
Material	Thermoplastic
Connection	Type C CEE 7/16 plug 6.3 mm Solder pins
Nominal voltage	250 V/AC
Nominal current	16 A
Mechanical life	300,000 switching cycles
Front panel thickness	2 mm
Front panel cut-out	22 x 30.2 mm
Product type	Power switch
Operating temperature range	-10 to +80 °C
Dimension (L x W x H)	38 x 40.5 x 29 mm

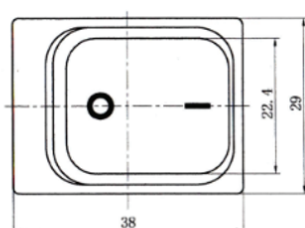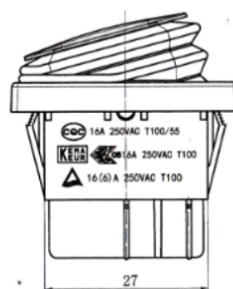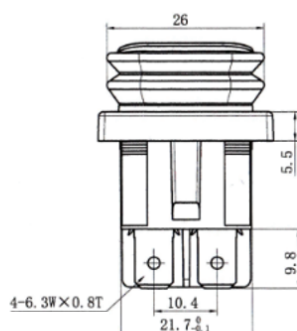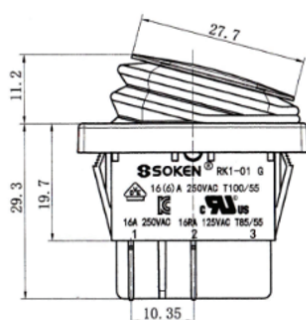

t	X	Y
0.75-1.25	30.0 ^{+0.1}	22 ^{+0.1}
1.25-2.0	30.2 ^{+0.1}	22 ^{+0.1}
2.0-3.0	30.5 ^{+0.1}	22 ^{+0.1}

 

TOLERANCES UNLESS OTHERWISE	
BASIC DIMENSION TOLERANCES	
UP TO 10	±0.3
ABOVE 10 TO 100	±0.5
ABOVE 100	±0.8
ANGULAR DIMENSIONS	±3°