


DATASHEET

Rocker switch

Item No. 3399886

Overview

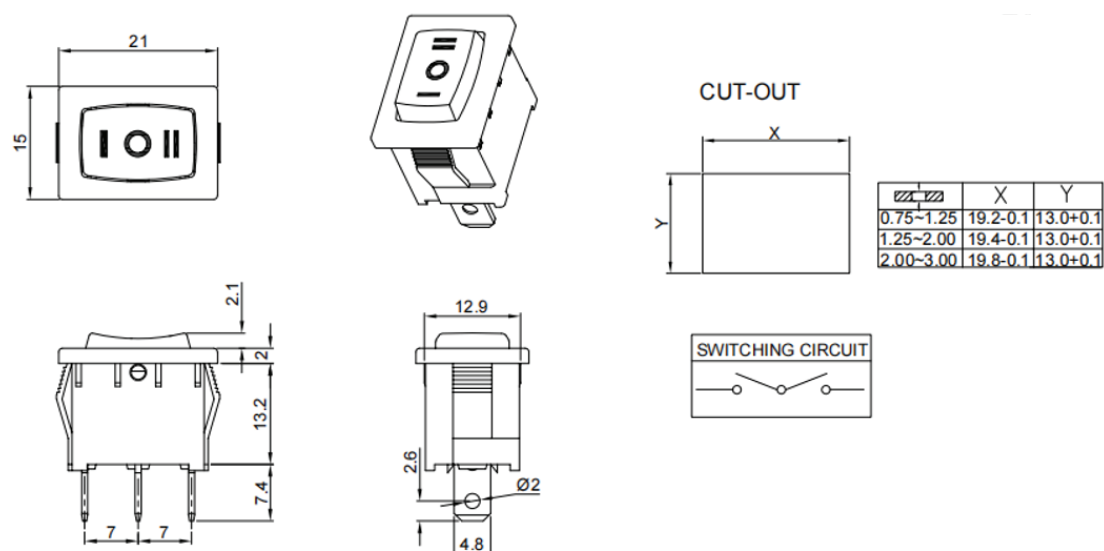

Technical data

Casing/button colour.....	Black
Functions	Latching / O / latching
Switch.....	SPDT
Switch position.....	1 x On/Off/On
Material.....	Thermoplastic
Connection	Flat plug 4.8 mm (3/16 "), Solder pins
Switching voltage.....	250 V/AC
Switching current.....	6 A
Contact resistance.....	max. 50mΩ
Insulation resistance.....	500 V/DC, min. 100 MΩ
Dielectric strength.....	1500V/AC, 1 minute
Dielectric life	10,000 cycles
Front panel thickness	2 mm
Front panel cut-out	13 x 19.4 mm
Connection	Solder connection
Product type	Toggle switch
Operating temperature range	-10 to +80 °C
Dimension (L x W x H).....	21 x 15 x 24.7 mm

