

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MP-4 SPRING BASKET PLUG



Item no. 3400587 (Red)

Item no. 3400588 (Black)


The 4 mm safety plug is used for the direct connection of stripped stranded wires from 0.5 to 2.5 mm². It is compatible with 4 mm safety sockets and provides a secure and reliable connection.

FEATURES

CAT II 600V 10A (max. 20A) // 4mm straight plug // double insulation cable

TECHNICAL DATA

Rated current	10A (max. 20A)
Nominal voltage	600 V
Connection	Tension spring
Type of insulation	Fully insulated
Cross section min.	0.5 mm ²
Cross section max.	2.5 mm ²
Pin diameter	4 mm
Design	Straight plug
Insulation material	PA
Cable material	PVC
Connection	Spring force
Contact material	Nickel-plated
Operation condition	-40 - 80 °C, < 80% RH
Storage condition	-40 - 80 °C, < 80% RH
Directly connect stripped strands	0.5 - 2.5 mm ²
Dimensions (L x W x H)	54 x 23.5 x 10 mm
Weight	approx. 40 g

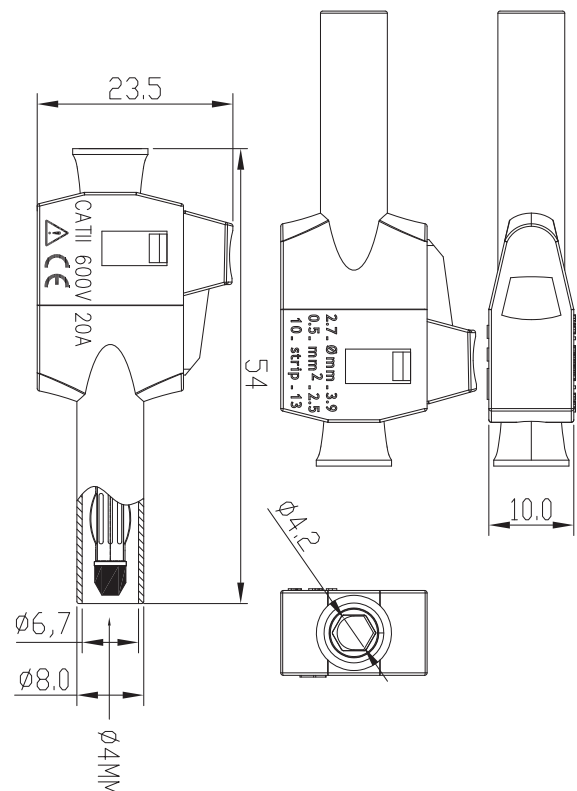

PACKAGE CONTENTS

Terminal plug set (50 pcs)