



SPECIFICATIONS

Product Name	MAG PANO 110R PZ / WHITE
Form Factor	Mid-Tower
I/O Ports	1 x USB 20Gbs (Type-C) 2 x USB 5Gbs (Type-A) 1 x Audio-Out / Mic-in 1 x LED Button 1 x Power Button
Drive Bays	2 x 2.5" 2 x 3.5" 2 x 2.5"/3.5" combo
Case Expansion Slots	7
Maximum PSU Length	200 mm / 7.87 inches
Maximum GPU Length	400 mm / 15.75 inches
Maximum CPU Cooler Length	160 mm / 6.30 inches
Lighting	Side: 3 x ARGB Fan (Reverse Blades Fan) Rear: 1 x ARGB Fan
Power Supply Support	ATX
Fan Support	Top: 3 x 120 mm / 2 x 140 mm Front: NA Rear: 1 x 120 mm Side: 3 x 120 mm / 2 x 140 mm Bottom: 3 x 120 mm (Above the power shroud)
Pre-install Fan	Side: 3 x 120 mm Rear: 1 x 120 mm
Radiator Layout	Top: 120 / 140 / 240 / 280 / 360 mm Front: NA Rear: 120 mm Side: NA Bottom: NA
Support MB Form Factor	Regular: ATX / Micro-ATX / Mini-ITX Back-connect: ATX / Micro-ATX
Dimension	420 x 225 x 485 mm / 16.54 x 8.86 x 19.09 inches

CONNECTIONS

FEATURES



Support Back-Connect Motherboard

Back-Connect PROJECT ZERO motherboards simplify cable management, providing a clear and aesthetic pleasing system setup.



Upgrade Airflow Layout

This model support maximizes up to 10 fans and a 360 mm radiator on top. The lower chamber, surrounded by vents further enhance heat dissipation for optimal performance.



270-Degree Display

The chassis features a 270-degree panoramic design with 3 mm tempered glass, offering an expansive view to showcase detailed components.




1 to 5 ARGB-FAN Control Board

This fan control board supports up to 5 x ARGB fans, allowing users to adjust the ARGB lighting effect with single one LED switch button.



Pre-build with Reverse Blades Fan

Pre-installed reverse blade fans on the side allow the unobstructed display of the ARGB fan's beauty without any interference from fan frames.

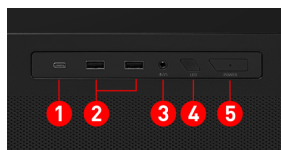

1. 1 x USB 20Gbs (Type-C)
2. 2 x USB 5Gbs (Type-A)
3. Mic In/ Audio Out
4. LED Button
5. Power Button