


## Plugs

### ASS 4-2

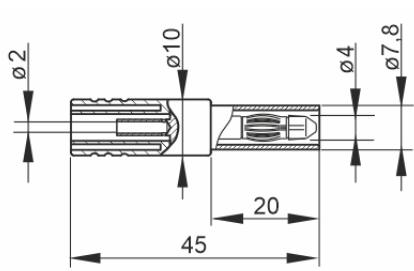

| Product                                                                        | ASS 4-2                                                                                                                                                       |
|--------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------|
| description                                                                    | Touch-protected safety adapter with spring-loaded 4 mm safety plug and rigid 2 mm safety socket for connection of 2 mm safety plugs, 1000 V system, IEC61010. |
| operating instruction                                                          | BA466                                                                                                                                                         |
| article-no. /<br>*colour                                                       | <div> <div>●</div> <div>00<br/>black</div> </div> <div> <div>●</div> <div>01<br/>red</div> </div>                                                             |
| drawing                                                                        |                                                                                                                                                               |
|                                                                                |                                                                           |
| technical data                                                                 |                                                                                                                                                               |
| connection                                                                     | unsprung socket 2 mm                                                                                                                                          |
| rated voltage                                                                  | AC/DC 1000 V                                                                                                                                                  |
| measurement cat. acc. to IEC 61010                                             | CAT III                                                                                                                                                       |
| rated current<br>(consider derating curve)                                     | 10 A                                                                                                                                                          |
| material socket                                                                | brass, nickel plated                                                                                                                                          |
| housing material                                                               | PA                                                                                                                                                            |
| temperature range acc. To IEC61010 <sup>(1)</sup>                              | -15 °C to +70 °C                                                                                                                                              |
| flammability class acc. to UL 94<br>(only valid for basic material of housing) | V-2                                                                                                                                                           |

<sup>(1)</sup> contact the manufacturer for applications at deviating temperature ranges  
stand: 28.11.2024

stand: 28.11.2024