




Javelot Turbo 2

Illuminate the Distance with Wireless Ease

MAX OUTPUT	MAX RUNTIME	MAX THROW	REMOTE CONTROL RANGE
			
1,800 lumens	272 hours	1,500 meters	8 meters

*This information is for market reference only. Please DO NOT make it public.

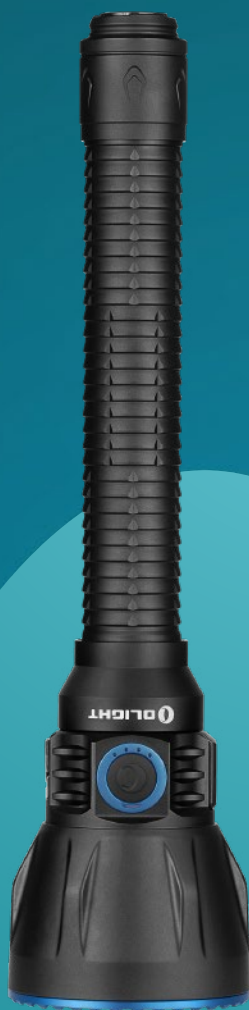

▲ BLACK



▲ OD GREEN

Javelot Turbo 2

Illuminate the Distance with Wireless Ease



MARKET APPLICATIONS

Hunting
Search and Rescue
Security
Law Enforcement

UPC:

6975498003992 (Black)
6977261691633 (OD Green)

DESCRIPTION

The Javelot Turbo 2 is a full-size, long-range flashlight designed for hunting or search-and-rescue applications. At maximum output, it can throw a focused beam of 1,800 lumens up to 1,500 meters away. Furthermore, the light can pair with a wireless remote, allowing control from 8 meters away. The magnetic dock on the flashlight secures the remote and charges it simultaneously. Powered by a 5,000 mAh battery pack, it offers up to 272 hours of runtime and can be easily replaced by unscrewing the tail cap. With both USB-C and magnetic charging capabilities, the flashlight provides exceptional charging flexibility. It can also be mounted to a setup using the X-WM03 magnetic mount, transforming it into a super long-range WML. Whether you're hunting, searching for a lost person, or checking the backyard, the Javelot Turbo 2 is exactly what you need.



FEATURES

- **Unmatched Long-Range Illumination:** The intense LED and deep reflector deliver 1,800 lumens with a 1,500-meter reach on Turbo mode.
- **Convenient Wireless Remote:** Paired with the flashlight, the remote allows control from up to 8 meters away. It is held securely in place and charges via the magnetic dock on the flashlight.
- **Huge and Replaceable Battery Pack:** Powered by a 5,000 mAh battery pack, the flashlight offers up to 272 hours of runtime on the lowest setting. The battery is quick to replace by unscrewing the tail cap.
- **Two Charging Methods:** The flashlight features USB-C and magnetic charging capabilities, ensuring maximum charging convenience and flexibility.
- **Two Switches for Easy Operation:** Equipped with a large, easy-to-locate side switch for adjusting brightness and a tail switch for split-second activation.
- **Doubles as a WML:** The Javelot Turbo 2 can be easily mounted to a setup and secured firmly with the X-WM03 magnetic mount.

SPECIFICATIONS

SPECIFICATIONS	Turbo	High	Medium	Low
	1,800~800~600 lumens	600~150 lumens	150 lumens	15 lumens
	4.5+130+120 minutes	360+30 minutes	30 hours	272 hours
	1,500 meters	860 meters	430 meters	136 meters
	576,715 cd	192,448 cd	47,925 cd	4,627 cd

* All data above are test results according to ANSI/NEMA FL 1-2019 standards.

IP RATING IP67



DROP TEST



COMPLIANCE



olight.com © OLIGHT 01/16/25 V1
 Made in China

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.

DIMENSIONS

2.48 x 10.14 in (63 x 257.6 mm)

WEIGHT

15.17 oz (430 g)

BODY MATERIAL

6061-T6 Aluminum Alloy

BATTERY

5,000 mAh Lithium-ion Battery Pack

WARRANTY

Lifetime Warranty in Australia, China, France, Germany and the USA.
 5-Year Warranty in other countries and regions.

IN THE BOX

Javelot Turbo 2:

Javelot Turbo 2 (Battery Pack Included) x 1
 Flashlight Holster x 1
 Flashlight Case x 1
 Wireless Remote x 1
 Remote Mount x 1
 Lanyard x 1
 USB-C Charging Cable x 1

Javelot Turbo 2 Kit:

Javelot Turbo 2 (Battery Pack Included) x 1
 X-WM03 Magnetic Mount x 1
 Green Filter x 1
 Red Filter x 1
 Flashlight Case x 1
 Wireless Remote x 1
 Remote Mount x 1
 Lanyard x 1
 USB-C Charging Cable x 1

Optional Accessories

Javelot Turbo 2 Battery Pack
 Wireless Remote Kit
 Variable Scope Mount
 sROD Remote Pressure Switch
 X-WM03 Magnetic Mount
 Green Filter
 Red Filter
 MCC3 Charging Cable