


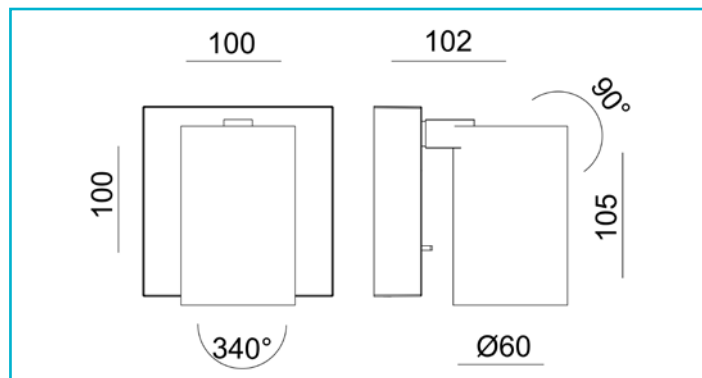

The square CAN reading light is the ideal choice for modern hotel rooms and sophisticated living spaces. It offers a convenient charging option for smartphones and other devices via USB-C and USB-A (article no. 341339 and 341340 only). The widely used GU10 base enables the quick replacement of the lamp, while the screw-on cylinder housing allows tool-free access. Individual accents can be set with the optional, replaceable decorative rings. The CAN reading light is part of a versatile lighting family, which is also available as a pendant, ceiling, wall and outdoor light.

Special features

- Flat and discreet lamp base
- Replaceable lamp to offer an individual lighting solution
- Can be customised with a wide range of accessories
- Can be combined with the comprehensive product family of the CAN series
- Can be charged via USB-C/USB-A [art. nos. 341339 and 341340 only]

Housing Material	Aluminium
Housing Color	Black
Material of Lens	Polycarbonate - PC
Protection Class	Protection class I/protective grounding
max. Power	1x max. 7.5 W
Rated Input Voltage	220-240 V/AC
Socket Description	GU10
Socket Quantity	1 PCS
Connection Type	Clamp
Dimmable	Yes
Control	Dimmable via optional light source
Motion Detector	No
Execution	Without lamp
Swivel Angle	90 Degree
Rotation Angle	355 Degree
Light Exit Surfaces	1
Light characteristics	Direct
Light direction	Below
Length	102 mm
Height	105 mm
Diameter	60 mm
Base width	100 mm
Base height	100 mm
Product weight	346 g
IP Protection Class	IP 20