


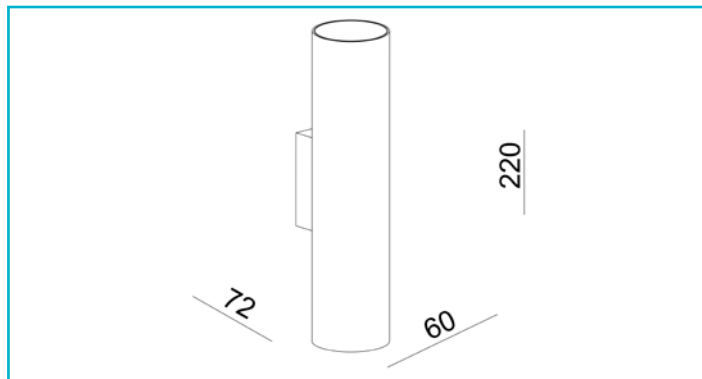

The CAN wall light provides versatile lighting options for various commercial and private projects. The up/down variant with light emission on both sides can be adapted perfectly to individual room concepts. The GU10 base enables simple replacement of the lamp, while the screw-on cylinder allows tool-free access. Installation for rigid and flexible conductors is particularly easy due to the integrated push terminals. Individual accents can be created with the optional, interchangeable decorative rings. The CAN wall light is part of a comprehensive series and is also available as a pendant, ceiling, reading and outdoor light.

Special features

- USP
- USP
- USP
- USP
- USP

Housing Material	Aluminium
Housing Color	Black
Material of Lens	Polycarbonate - PC
Protection Class	Protection class I/protective grounding
max. Power	2x max. 7.5 W
Rated Input Voltage Frequency	220-240 V/AC 50 / 60 Hz
Socket Description	GU10
Socket Quantity	2 PCS
Connection Type	Clamp
Dimmable	Yes
Control	Dimmable via optional light source
Motion Detector	No
Execution	Without lamp
Light Exit Surfaces	2
Light characteristics	Direct, Indirect
Light direction	Top, Below
Length	72 mm
Height	230 mm
Diameter	60 mm
Product weight	373 g
IP Protection Class	IP 20