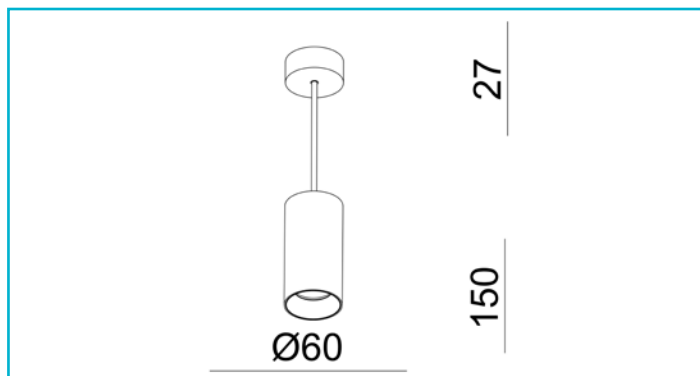


**Special features**

- Flat and discreet lamp base
- Can be customised with a wide range of accessories
- Replaceable lamp to offer an individual lighting solution
- Can be combined with the comprehensive CAN series product family

Housing Material	Aluminium
Housing Color	Black
Material of Lens	Polycarbonate - PC
Protection Class	Protection class I/protective grounding
max. Power	1x max. 7.5 W
Rated Input Voltage Frequency	220-240 V/AC 50 / 60 Hz
Socket Description	GU10
Socket Quantity	1 PCS
Connection Type	Clamp
Dimmable	Yes
Control	Dimmable via optional light source
Motion Detector	No
Execution	Without lamp
Light Exit Surfaces	1
Light characteristics	Direct
Light direction	Below
Height	150 mm
Diameter	60 mm
Base height	27 mm
Base diameter	60 mm
Pendulum Length max.	1500 mm
Product weight	413 g
IP Protection Class	IP 20