


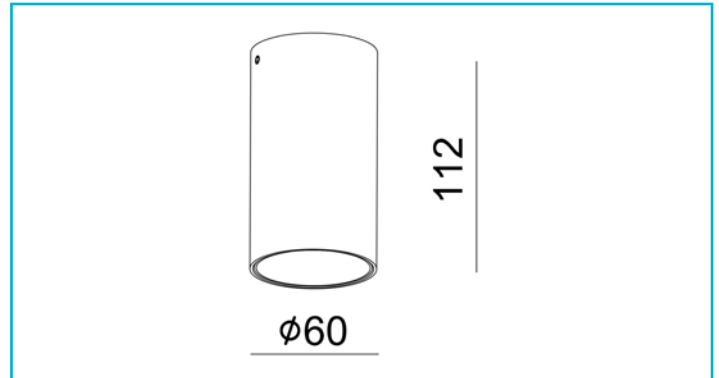

The CAN surface-mounted ceiling light provides a robust and flexible lighting solution for commercial and private applications. The GU10 base enables quick and simple replacement of the lamp, while the screw-on cylinder housing allows tool-free access. Push terminals for rigid and flexible conductors facilitate installation. The CAN surface-mounted ceiling light is part of a comprehensive light series and is also available as a pendant, wall, reading and outdoor light.

**Special features**

- USP
- USP
- USP
- USP
- USP

|                                      |                                           |
|--------------------------------------|-------------------------------------------|
| <b>Housing Material</b>              | Aluminium                                 |
| <b>Housing Color</b>                 | White                                     |
| <b>Material of Lens</b>              | Polycarbonate - PC                        |
| <b>Protection Class</b>              | Protection class II/protective insulation |
| <b>max. Power</b>                    | 1x max. 7.5 W                             |
| <b>Rated Input Voltage Frequency</b> | 220-240 V/AC 50 / 60 Hz                   |
| <b>Socket Description</b>            | GU10                                      |
| <b>Socket Quantity</b>               | 1 PCS                                     |
| <b>Connection Type</b>               | Clamp                                     |
| <b>Dimmable</b>                      | Yes                                       |
| <b>Control</b>                       | Dimmable via optional light source        |
| <b>Motion Detector</b>               | No                                        |
| <b>Execution</b>                     | Without lamp                              |
| <b>Light Exit Surfaces</b>           | 1                                         |
| <b>Light characteristics</b>         | Direct                                    |
| <b>Light direction</b>               | Below                                     |
| <b>Height</b>                        | 105 mm                                    |
| <b>Diameter</b>                      | 60 mm                                     |
| <b>Product weight</b>                | 176 g                                     |
| <b>IP Protection Class</b>           | IP 20                                     |