


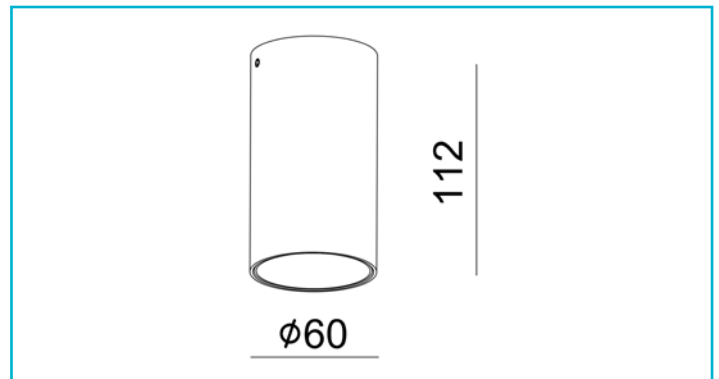

The CAN surface-mounted ceiling light provides a robust and flexible lighting solution for commercial and private applications. The GU10 base enables quick and simple replacement of the lamp, while the screw-on cylinder housing allows tool-free access. Push terminals for rigid and flexible conductors facilitate installation. The CAN surface-mounted ceiling light is part of a comprehensive light series and is also available as a pendant, wall, reading and outdoor light.

Special features

- USP
- USP
- USP
- USP
- USP

Housing Material	Aluminium
Housing Color	Black
Material of Lens	Polycarbonate - PC
Protection Class	Protection class II/protective insulation
max. Power	1x max. 7.5 W
Rated Input Voltage Frequency	220-240 V/AC 50 / 60 Hz
Socket Description	GU10
Socket Quantity	1 PCS
Connection Type	Clamp
Dimmable	Yes
Control	Dimmable via optional light source
Motion Detector	No
Execution	Without lamp
Light Exit Surfaces	1
Light characteristics	Direct
Light direction	Below
Height	105 mm
Diameter	60 mm
Product weight	176 g
IP Protection Class	IP 20